

MULTIPURPOSE DIAGONAL CUTTING

| PART NO. | SIZE INCH | L MM | a MM | G.W. (kg) |
|----------|-----------|------|------|-----------|
| 72701    | 6"        | 175  | 67   | 5.9       |



PLASTIC CUTTING

| PART NO. | SIZE INCH | L MM | a MM | G.W. (kg) |
|----------|-----------|------|------|-----------|
| 70641    | 5"        | 125  | 67   | 13.0      |
| 70642    | 6"        | 150  | 67   | 19.0      |
| 70643    | 7"        | 175  | 67   | 12.0      |

- For cutting plastic/Vinyl coated cable.
- Not for use in cutting metal material.


ANSI B107.11M

⚠ Nature of this product is subject to wear and tear upon usage. Not covered under Lifetime Warranty.




D-SUB CONTACT CRIMPING TOOL

| PART NO. | SIZE INCH | L MM | a MM | G.W. (kg) |
|----------|-----------|------|------|-----------|
| 91101    | 8"        | 204  | 67   | 14.9      |

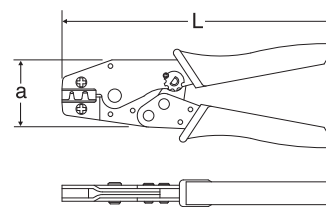


CABLE FERRULES CRIMPING TOOL

| PART NO. | SIZE INCH | L MM | a MM | G.W. (kg) |
|----------|-----------|------|------|-----------|
| 91102    | 8"        | 204  | 67   | 14.2      |

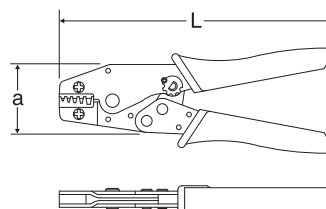


COAX CRIMPING TOOL

| PART NO. | SIZE INCH | L MM | a MM | G.W. (kg) |
|----------|-----------|------|------|-----------|
| 91104    | 9-1/2"    | 204  | 67   | 23.1      |

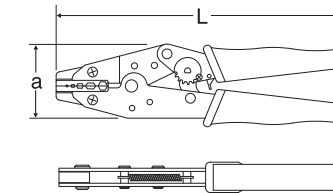


HEAVY DUTY CRIMPING TOOL

| PART NO. | SIZE INCH | L MM | a MM | G.W. (kg) |
|----------|-----------|------|------|-----------|
| 91105    | 9"        | 240  | 67   | 18.9      |

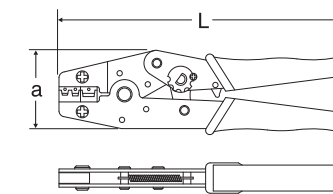

HEAVY DUTY NON-INSULATED CRIMPING TOOL

| PART NO. | SIZE INCH | L MM | a MM | G.W. (kg) |
|----------|-----------|------|------|-----------|
| 91106    | 10-1/4"   | 262  | 76   | 19.7      |

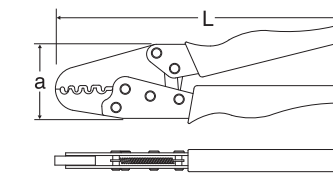

TAB CONNECTOR CRIMPING TOOL

| PART NO. | SIZE INCH | L MM | a MM | G.W. (kg) |
|----------|-----------|------|------|-----------|
| 91107    | 9"        | 228  | 67   | 22.9      |

