




ENGLISH

Datasheet

RS 8 Core Unscreened Industrial Cable, PVC Sheath, 5.8mm OD, 0.22 mm² CSA 1 A, 440 V, 100m

Stock Number - 660-4055

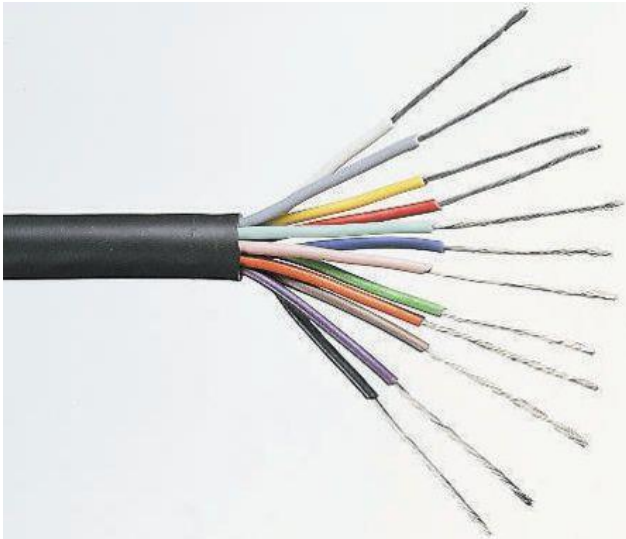

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V):440

Flammability Test: IEC60332-1



ENGLISH

Construction:

Conductor: Tinned Copper

Conductor Dia. (mm): $0.20 \pm 0.008 \times 7$

Insulation: PVC

Insulation Dia. (mm): $1.2 \pm 0.05 \times 8C$

Fiiler: 1.9 PVC Strip

Tape: Mylar Spiral

Coverage: $\geq 115\%$

ID Thread : Green, White/Green

A rip cord : 210 D

Jacket: FR-PVC

Outer Dia. (mm): 5.6 ± 0.1

Colour:

The colour of the insulation: Red , Blue
, Green , Yellow ,

White , Black , Brown , Violet

The jacket colour: Black

Marking(3times/m):

RS 6604055 7 - 2 - 8A

Performance:

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω /Km) :

<92

Min.Insulation DC Resistance at 20°C ($M\Omega$ *KM) :

>200

Current Rating : 1 A

