


RVV

PVC Insulated PVC Sheathed Soft Wire

铜芯聚氯乙烯绝缘聚氯乙烯护套软电线

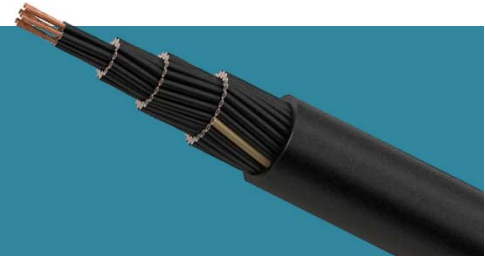

Application

- These cables are suitable for use of rate voltage 300/500V and below power plsnt, fixed wiring and flexible connection for electrical appliances.

Construction

- Conductor: Flexible bare, annealed copper, acc to IEC60228 - 2004 class5
- Insulation: Polyvinyl chloride (PVC)
- Sheath: Polyvinyl chloride (PVC)
- Color: Bleck Grey or customer-specified

Technical Data

- Nominal voltage: 300/500V
- Temperature range : 0°C~70°C

Standards / Material properties

- Approvals: CCC; CE
- Application standards: GB/T 5023-2008; IEC 60227

Type selection

Cores×cross-sec	Insulation Thickness	Sheath Thickness	Outerø	Weight
Nr×mm ²	mm	mm	ca,mm	ca,kg/km
2×0,75	0,6	0,8	7,6	49,24
2×1	0,6	0,8	8	56,59
2×1,5	0,7	0,8	9	74,6
2×2,5	0,8	1	11	113,45
*2×4	0,8	1,1	12,4	159,13
*2×6	0,8	1,2	14,6	224,88
3×0,75	0,6	0,8	8	61,23
3×1	0,6	0,8	8,4	71,27
3×1,5	0,7	0,9	9,8	99,3
3×2,5	0,8	1,1	12,0	150,53
*3×4	0,8	1,1	13,2	207,94
*3×6	0,8	1,2	15,6	295,07
4×0,75	0,6	0,8	8,6	75,12
4×1	0,6	0,9	9,4	91,72
4×1,5	0,7	1	11,0	127,54
4×2,5	0,8	1,1	13,0	187,6
*4×4	0,8	1,1	14,4	262,19
*4×6	0,8	1,2	17,1	373,26
5×0,75	0,6	0,9	9,6	93,53
5×1	0,6	0,9	10,0	109,73

Dimensions and specifications may be changed without prior notice

应用

- 本产品分别适用于额定电压300/500V及以下的动力装置、固定布线及挠性连接电器之用。

结构

- 导体：退火软铜线,符合IEC60228 -2004 五类导体
- 绝缘：聚氯乙烯
- 护套：聚氯乙烯
- 颜色：黑 灰或客户指定

技术参数

- 额定电压：300/500V
- 工作温度：0 °C~70 °C

标准 / 材料性能

- 认证: CCC; CE
- 应用标准: GB/T 5023-2008; IEC 60227

RVV

PVC Insulated PVC Sheathed Soft Wire

铜芯聚氯乙烯绝缘聚氯乙烯护套软电线



Type selection

Cores×cross-sec	Insulation Thickness	Sheath Thickness	Outerø	Weight
Nr×mm ²	mm	mm	ca,mm	ca,kg/km
5×1,5	0,7	1,1	12,0	157,85
5×2,5	0,8	1,2	14,0	231,99
*5×4	0,8	1,2	15,6	324,95
*5×6	0,8	1,3	18,5	462,32
*6×0,75	0,6	0,9	10,2	107,08
*6×1	0,6	0,9	10,7	126,09
*6×1,5	0,7	1	12,5	176,44
*6×2,5	0,8	1,1	14,9	261,82
*6×4	0,8	1,2	16,9	377,24
*6×6	0,8	1,4	20,3	545,26
*7×0,75	0,6	0,9	10,4	114,88
*7×1	0,6	0,9	10,9	136,04
*7×1,5	0,7	1	12,5	190,98
*7×2,5	0,8	1,1	15,0	284,93
*7×4	0,8	1,2	17,1	413,63
*7×6	0,8	1,4	20,5	596,97
*10×0,75	0,6	0,9	13,5	172,94
*10×1	0,6	0,9	14,2	204,16
*10×1,5	0,7	1	16,3	284,9
*10×2,5	0,8	1,1	19,3	430,41
*10×4	0,8	1,2	22,1	618,77
*10×6	0,8	1,4	16,5	889,08
*12×0,75	0,6	1,1	14,0	193,54
*12×1	0,6	1,1	14,9	235,5
*12×1,5	0,7	1,2	16,9	321,72
*12×2,5	0,8	1,4	19,9	487,87
*12×4	0,8	1,5	22,8	706,25
*12×6	0,8	1,7	27,4	1014,52
*14×0,75	0,6	1,1	14,8	225,53
*14×1	0,6	1,2	15,8	273,92

Dimensions and specifications may be changed without prior notice

RVV

PVC Insulated PVC Sheathed Soft Wire

铜芯聚氯乙烯绝缘聚氯乙烯护套软电线



Type selection

Cores×cross-sec	Insulation Thickness	Sheath Thickness	Outerø	Weight
Nr×mm ²	mm	mm	ca,mm	ca,kg/km
*14×1,5	0,7	1,2	18,1	381,69
*14×2,5	0,8	1,4	21,1	566,82
*14×4	0,8	1,5	24,3	830,34
*14×6	0,8	1,7	28,8	1166,02
*16×0,75	0,6	1,2	15,3	246,61
*16×1	0,6	1,2	16,3	300,67
*16×1,5	0,7	1,4	19,1	436,64
*16×2,5	0,8	1,7	22,1	638,98
*16×4	0,8	1,7	25,5	937,64
*16×6	0,8	1,7	30,2	1319,83
*19×0,75	0,6	1,5	16,3	289,1
*19×1	0,6	1,5	17,1	345,34
*19×1,5	0,7	1,7	19,9	493,43
*19×2,5	0,8	1,7	23,7	756,98
*19×4	0,8	1,7	26,9	1086,28
*19×6	0,8	1,8	31,9	1532,84
*24×0,75	0,6	1,2	19,2	384,99
*24×1	0,6	1,3	20,2	457,68
*24×1,5	0,7	1,4	23,5	648,44
*24×2,5	0,8	1,5	27,3	952,11
*24×4	0,8	1,7	31,0	1369,82
*24×6	0,8	1,7	37,3	1953,47

Dimensions and specifications may be changed without prior notice