


Deep groove ball bearings, single row, SKF Energy Efficient (E2) bearings



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			C	C_0	kN	r/min		kg	-
10	35	11	8,32	3,4	0,143	55000	29000	0,053	E2.6300-2Z/C3

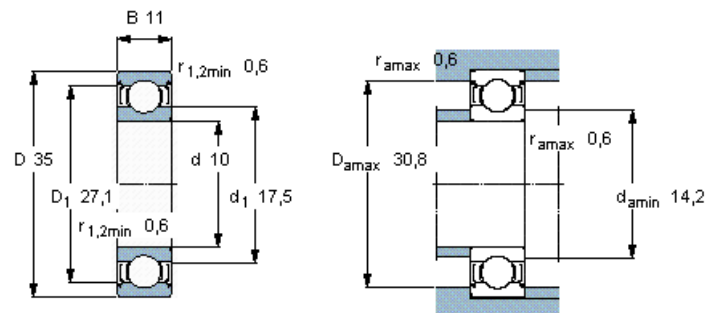

Calculation factors

k_f 0,03

f_0 11