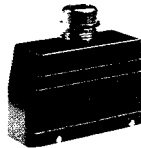
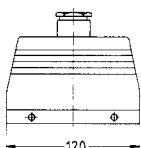
 
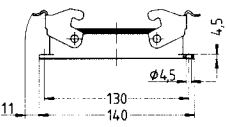
 
 
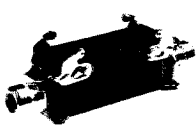
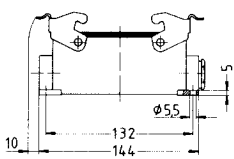
 


Locking clip on housing
 Locking bayonet on hood

Style	Ordering number	Cable entry			Description	Outline drawing dimensions in mm
Hood side entry high construction  		 PG	 PG	 PG		
	49.30.64.07 49.30.64.80 49.30.64.70 49.30.64.09 49.30.64.81 49.30.64.71	21	21	21	HD.64.STO.1.21 HD.64.STO.1.21.Z HD.64.STO.1.21.G HD.64.STO.1.29 HD.64.STO.1.29.Z HD.64.STO.1.29.G	 
	51.49.30.64.07 51.49.30.64.80 51.49.30.64.70 51.49.30.64.09 51.49.30.64.81 51.49.30.64.71	21	21	21	HD-K.64.STO.1.21 HD-K.64.STO.1.21.Z HD-K.64.STO.1.21.G HD-K.64.STO.1.29 HD-K.64.STO.1.29.Z HD-K.64.STO.1.29.G	
		29	29	29		
Surface-mounted housing bottom entry  	42.50.24.00				HB.24.AG-VS	 
	51.42.50.24.00				HB-K.24.AG-VS	
New!* With locking plugs  	19.42.50.24.00				HB-R.24.AG-VS	Panel cut-out  *New! Surface mounted housings (side entry) with locking flange for HD-DSTV-RA and DSTVK-RA inserts with locking clip for reverse mounting and screw mounting from the front side.
	59.42.50.24.00				HB-K/R.24.AG-VS	
Surface-mounted housing side entry standard construction  	42.60.24.16 42.60.24.80 42.60.24.17 42.60.24.96	21	21		HB.24.SG-VS.1.21 HB.24.SG-VS.1.21.Z HB.24.SG-VS.2.21 HB.24.SG-VS.2.21.Z	 
	51.42.60.24.07 51.42.60.24.80 51.42.60.24.08 51.42.60.24.96	21	21		HB-K.24.SG-VS.1.21 HB-K.24.SG-VS.1.21.Z HB-K.24.SG-VS.2.21 HB-K.24.SG-VS.2.21.Z	
		2x21	2x21			