



ENGLISH

## Datasheet

Stock No: 686-654

# RS Pro Black Phenolic Knob, M8 x 40



Standards  
BS771

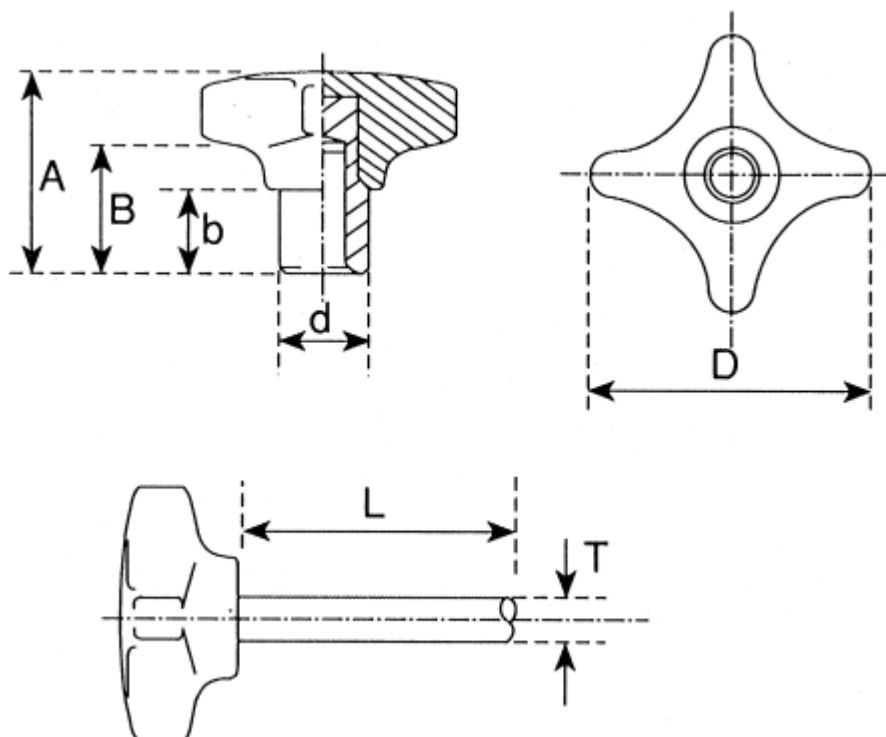
## Product Details

### Phenolic Cross Knobs

Wood filled phenolic knobs to BS771 with zinc plated steel threads and light alloy inserts and -30°C to + 140°C working range.

### Specifications:

Thread	M8 x 40
Thread Diameter	M8
Thread Length	40mm
Knob Shape	4-Arm
Mounting Type	Threaded Stud
Knob Diameter	50mm
Body Material	Phenolic
Insert Material	Alloy
Colour	Black

**Dimensions:**


Dimensions (mm)					
Stock no	D	A	B	b	d
686-604	38	20	8	-	18
686-610	38	20	8	-	18
686-626	38	20	8	-	18
686-632	50	27	12	-	22
686-648	50	27	12	-	22
686-654	50	27	12	-	22