
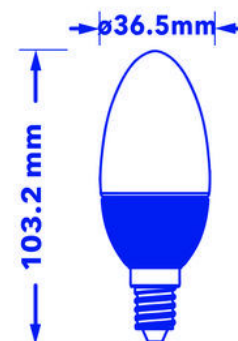


## Verbatim LED Candle Clear E14 5.5W 2700K Warm White 330 LM


- E14 Socket
- 220 - 240 V Voltage
- 15,000 hours Lifetime
- 82% Energy Saving
- Lumen: 330
- Equivalent to 30W incandescent bulb

Product Number	52604
<b>General Data</b>	
Lamp Socket	E14
<b>Electric Data</b>	
Wattage (W)	5.5
Wattage Equivalent (W)	30
Voltage (V)	220 - 240 V
Dimmable	no
Power Factor	0.50
Operating Frequency (Hz)	50-60
<b>Geometric Data</b>	
Length (mm)	103.2
Diameter (in mm)	36.5
Weight (g)	62
<b>Photometric Data</b>	
Luminous Flux (lm)	330
CRI	≥ 80
CCT (K)	2700
Beam Angle (°)	120
Luminous Efficacy (lm/W)	60
Lifetime (hrs)	15,000
Switching Cycle	20,000

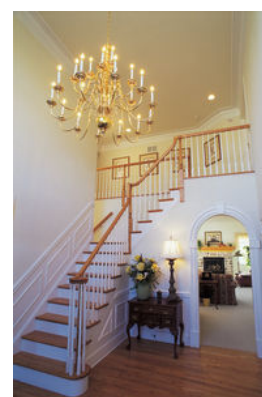


02/07/2014

## Photometric Diagrams

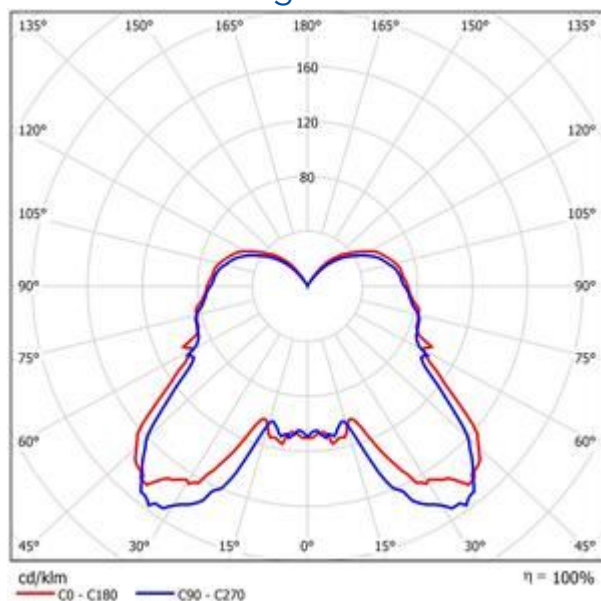

## Energy Rating

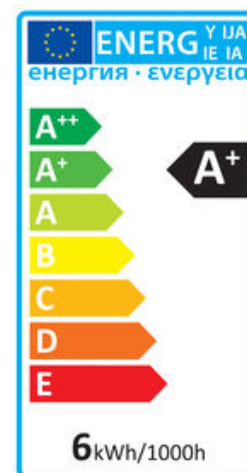

## Technical Packaging Details

**Barcode**

023942526049

**EAN 128**

(02)00023942526049(37)04(91)204

**EAN 14**

50023942526044

**Pack Dimensions(HxWxL)**

178 x 118 x 45

**Pack Weight**

96

**MOQ**

4

**Carton Dimensions (HxWxL)**

195 x 104 x 253

**Cartons/Pallet**

120

**Layers/Pallet**

4

**Units/Pallet**

480

02/07/2014