




ENGLISH

Datasheet

DC Axial Fan

RS Stock number 619-6674

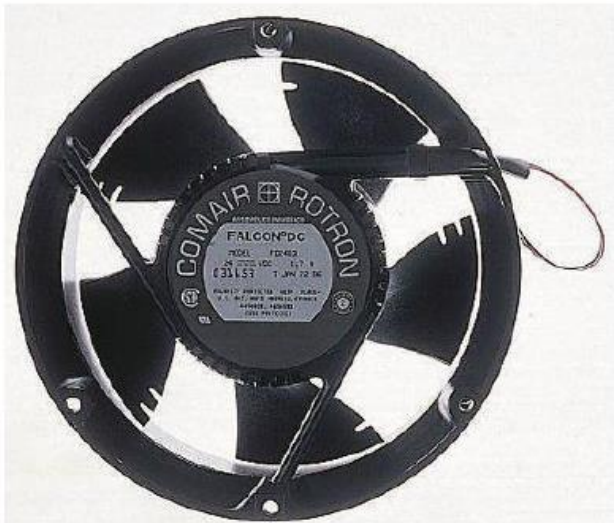

Frame

Diecast Aluminium

Impeller

Glass Reinforced PBT, UL94V-0

Available Options:

- Tachometer
- Locked Rotor Alarm
- PWM Input
- Thermal Speed Control

Finger Guard: G172-10HA, G172-10H, \G172-10LN

Plastic Guard: G172P

Aluminium Filter: WMG172M

Filter Kit: GRM172-45

Specifications:

RS Part Number	Orion Part Number	Speed (RPM)	Airflow (CFM)	Noise (db)	Volts (DC)	Voltage Range	Current (AMPs)	Connection Type
6196668	OD172AP-12HBX	3300	230	52	12	8~14	1.90	Wire
6196680	OD172AP-24HB	3300	235	52	24	12~28	0.97	Wire
6196674	OD172AP-24HBX	3950	300	57	24	12~28	0.97	Wire

Specifications:

Motor

Brushless DC, impedance and polarity protected, auto restart

Insulation Resistance

Min. 10M ohms at 500V dc

Life Expectancy (L10)

Ball Bearing 60,000 hours

Operating Temperature

-10C ~ +70C

Safety Approvals

UL/CUL, TUV, CE

Dimensions (mm):

