

88 05 250

KNIPEX Alligator® Water Pump Pliers



- More output and comfort compared to conventional water pump pliers of the same length: 9-notch adjustment positioning for 30 % more gripping capacity
- Good access to the workpiece due to slim size of head and joint area
- Self-locking on pipes and nuts: no slipping on the workpiece and low handforce required
- Gripping surfaces with special hardened teeth, teeth hardness approx. 61 HRC: high wear resistance and stable gripping
- Box-joint design for high stability due to double guide
- Robust construction, insensitive to dirt; particularly suitable for outdoor work
- Guard prevents operators' fingers being pinched
- Chrome vanadium electric steel, forged, multi stage oil-hardened
- With slim multi-component grips without collar for better handling and easier transport





Article No.	88 05 250
EAN	4003773039303
Pliers	chrome plated
Handles	with slim multi-component grips
Head	
Adjustment positions	9
Capacity for pipes, inches (diameter) Ø Inch	2
Capacities for nuts mm	46
Capacities for pipes (diameter) Ø mm	50
Length mm	250
Net weight g	344



Self-locking on pipes and nuts: no slipping on the workpiece; the complete actuating force can be used to turn the workpieces; not having to squeeze the pliers handles reduces the required effort



technical change and errors excepted

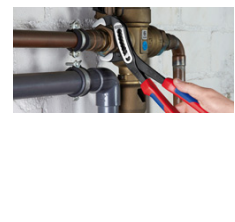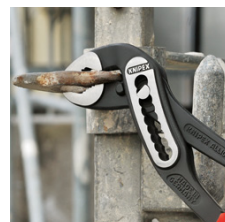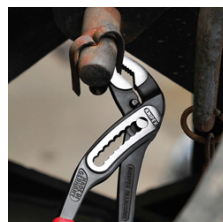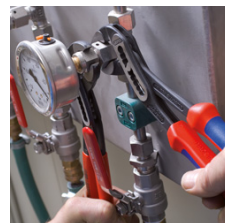

Spare Parts

Article No.	EAN	
88 09 250	4003773053514	Bolt (Kerpin) for 88 250