

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [130057-0001](#)  
**Status:** **Active**  
**Overview:** [industrial ethernet solutions](#)  
**Description:** Brad® RJ-Lnxx™, Threaded, RJ-45 Ethernet Field-Attachable Connector for Standard Core Cable

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Field Attachable / Accessories
Series	<a href="#">130057</a>
IP Rating	IP67
Overview	<a href="#">industrial ethernet solutions</a>
Product Name	Brad®, RJ-Lnxx®
Type	Field Attachable Connector
UPC	78678848445

**Physical**

Cable Diameter	N/A
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	None
Material - Connector Body	Polycarbonate
Material - Contact	Copper
Material - Coupling Nut	ABS
Material - Plating Mating	n/a
Net Weight	22.960/g
Orientation	Straight
Poles	N/A
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	N/A

**Electrical**


Current - Maximum per Contact	4A
Voltage - Maximum	250V

**Material Info**

Old Part Number	ENQAM315
-----------------	----------

**Reference - Drawing Numbers**

Sales Drawing	SD-130057-001
---------------	---------------

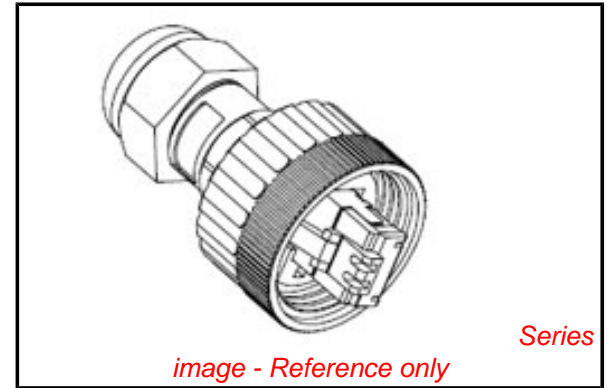

*image - Reference only*

**EU RoHS**

**ELV and RoHS  
Compliant**

**REACH SVHC**

Not Reviewed

**Low-Halogen Status**

**Low-Halogen**

**China RoHS**



**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

130057Series