




ENGLISH

Datasheet

Stock No: 522-446

RS Pro 3 Core YY Control Cable Unscreened Polyvinyl Chloride PVC Sheath

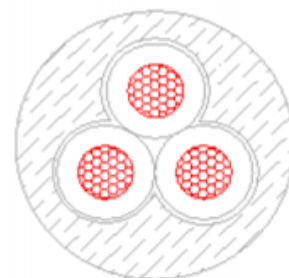

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Electrical Characteristics:

Max. Conductor DC Resistance at 20°C (Ω/Km):
<21.1

Min. Insulation DC Resistance at 20°C ($\text{M}\Omega \cdot \text{KM}$):
>500

Current Rating : 10 A

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.20 \pm 0.008 \times 32$

Insulation: PVC

Insulation Dia. (mm): $2.52 \pm 0.1 \times 3\text{C}$

Filler: Chalk

Jacket: PVC

Outer Dia. (mm): 6.55 ± 0.25

Colour:

The colour of the insulation: Black
x 2 , Yellow/Green

The jacket colour: Grey (RAL-7001)

Marking (3 times/m):

RS 522446 YY/NR 3 Core x 1.0mm²