

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [35725-2410](#)  
**Status:** **Active**  
**Overview:** Standard Quick-Disconnect Terminals  
**Description:** Quick Disconnect, Female, for 14-18 AWG (2.00 - 0.80mm<sup>2</sup>) Wire, Metal Strip, Tab 6.35 x 0.81mm, Slip-On Type with Slot, Post Tin Plating

**Documents:**

[Drawing \(PDF\)](#) [Packaging Specification PK-35725-015 \(PDF\)](#)  
[Product Specification PS-35703-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Packaging Specification PK-35725-012 \(PDF\)](#)

**Agency Certification**

CSA LR95446  
 UL E92853

**General**

Product Family Quick Disconnects  
 Series [35725](#)  
 Crimp Quality Equipment Yes  
 Insulated No  
 Overview [Standard Quick-Disconnect Terminals](#)  
 Product Name N/A  
 Type Quick Disconnect  
 UPC 800753514645

**Physical**

Barrel Type Open  
 Gender Female  
 Glow-Wire Compliant No  
 Insulation None  
 Lock to Mating Part Yes  
 Material - Metal Brass  
 Material - Plating Mating Tin  
 Material - Plating Termination Tin  
 Net Weight 0.840/g  
 Orientation Straight  
 Packaging Type Reel  
 Plating min - Mating 1.016µm  
 Plating min - Termination 1.016µm  
 Polarized to Mating Part No  
 Tab Thickness 0.81mm  
 Tab Width 6.35mm  
 Temperature Range - Operating -40°C to +120°C  
 Termination Interface: Style Crimp or Compression  
 Wire Insulation Diameter 3.81mm max.  
 Wire Size AWG 14, 16, 18  
 Wire Size mm<sup>2</sup> 0.80 - 2.00


**Electrical**

Voltage - Maximum 300V

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification PK-35725-012, PK-35725-015  
 Product Specification PS-35703-001  
 Sales Drawing SD-35725-002

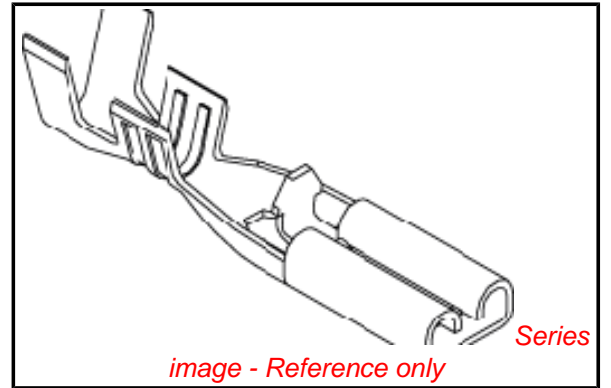

**EU RoHS**

**ELV and RoHS Compliant**  
**REACH SVHC Contains SVHC: No**  
**Low-Halogen Status Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

[35725Series](#)

**Use With**

6.35mm Tab

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

Description	Product #
Hand Tool for .250 Slip-in Receptacle Terminals for 14-18 AWG Wire.	<a href="#">0638272100</a>

This document was generated on 02/24/2015

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**