

## Classic ECO Ball

CLECO BAL 230V 18W E27 SV1

0023716



### Range features

- 1:1 replacement of Incandescent Ball lamp
- More efficient - more savings
- Excellent colour rendering (CRI = 100)
- Instant illumination
- Sparkling light output
- Less heat generation than incandescent lamp
- Less CO2 emissions
- Identical shape as standard incandescent lamp
- Commercial and domestic application
- 100% dimmable
- Average rated life 2000 hrs - up to two times more average life compared to incandescent lamps



### PRODUCT OVERVIEW

Light colour	828 Homelight
Technology	Halogen
Ordering number	0023716
Average life (Rated) (h)	2000
Energy class	D
Lamp shape	Ball
Lamp finish	Clear
Dimmable	Yes
Cap/Base	E27
Type	Ball ECO
EAN code	5410288237169
CRI (Ra)	100
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	205
Watt (Nominal) (W)	18
Equivalent watt (W)	24
Voltage (V)	230

## Classic ECO Ball

CLECO BAL 230V 18W E27 SV1

0023716

### DATA TABLE

#### General data

<b>Ordering number</b>	0023716
<b>Technology</b>	Halogen
<b>Average life (Rated) (h)</b>	2000
<b>Average life (Nominal) (h)</b>	2000
<b>Energy saving lamp</b>	No
<b>Energy class</b>	D
<b>Lamp finish</b>	Clear
<b>Lamp shape</b>	Ball
<b>Dimmable</b>	Yes
<b>Cap/Base</b>	E27
<b>Type</b>	Ball ECO
<b>EAN code</b>	5410288237169
<b>Long description</b>	1:1 replacement of Incandescent Ball lamp. More efficient - more savings. Excellent colour rendering (CRI = 100). Instant illumination. Sparkling light output. Less heat generation than incandescent lamp. Less CO2 emissions. Identical shape as standard incandescent lamp. Commercial and domestic application. 100% dimmable. Average rated life 2000 hrs - up to two times more average life compared to incandescent lamps
<b>Product name</b>	CLECO BAL 230V 18W E27 SV1
<b>Lamp mercury content (mg)</b>	0
<b>Starting time (max) (s)</b>	0.01
<b>Warm-up time to 60% of full light (max) (s)</b>	Instant full light
<b>Control gear required</b>	No
<b>Fixture rating</b>	Open
<b>IEC Reference</b>	IEC 60357
<b>IEC Reference 2</b>	IEC 60432-2
<b>Intended purpose</b>	General lighting
<b>No. of switching cycles before premature failure (min)</b>	> 8000
<b>Special purpose lamp</b>	No
<b>Transformer required</b>	No
<b>Sales pack quantity</b>	10
<b>Optimal operating condition (°C)</b>	25

# Classic ECO Ball

CLECO BAL 230V 18W E27 SV1

**0023716**

## Optical data

Light colour	828 Homelight
CRI (Ra)	100
Suitable for accent lighting	No
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	205
Lumen maintenance at end of nominal life (%)	80
Luminous flux (Nominal) (lm)	205

## Electrical data

kWh per 1000 hours burning time	18
Watt (Rated) (W)	18
Watt (Nominal) (W)	18
Equivalent watt (W)	24
Voltage (V)	230
Lamp power factor	1

## Physical data


Weight (kg)	0.02
Lamp Length (mm) - C/L	74
Max. Lamp Diameter (mm) - D	46
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	7.60 x 4.55 x 4.55
Inner package dimensions (L x W x H) (cm)	23.50 x 10.00 x 8.50
Inner package net weight (kg)	0.19
Outer package dimensions (L x W x H) (cm)	52.00 x 25.50 x 19.00

## Classic ECO Ball

CLECO BAL 230V 18W E27 SV1

0023716

### TECHNICAL DRAWINGS

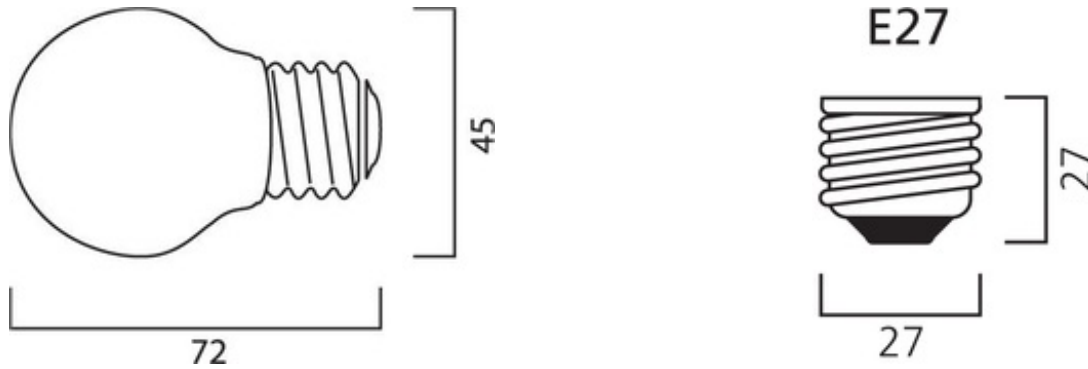

### ENERGY LABEL

