


## Datasheet

# DPDT Toggle Switch On-Off-On, 5 A@ 125 V ac, 5 A@28 V dc, Panel Mount

RS Stock number [448-0775](#)

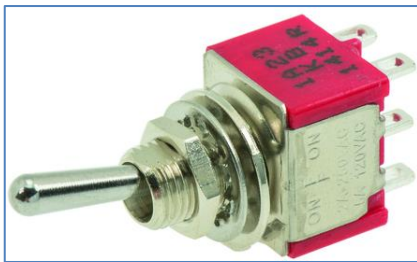


## Description:

Miniature toggle switches.

- Silver contacts
- Solder tag terminals
- Suitable for moderate duty applications
- Brass actuator, diallyl phthalate case and stainless steel housing

## Specifications:

Actuator Length:	10.41mm
Actuator Material:	Chromium Plated Brass
Contact Configuration:	DPDT
Contact Current Rating:	5 A@ 125 V ac, 5 A@ 28 V dc
Contact Material:	Silver Plated Brass (Movable)
Contact Resistance:	10mΩ
Electrical life:	50,000 make and break cycles at full load
Dielectric Strength:	1500 VRMS @ sea level
Insulation Resistance:	1000 MΩ min.
Operating Temperature:	-30°C to +85°C
Mounting Type:	Panel Mount
Panel Cut Out Diameter:	6.35mm
Panel Cut Out Size:	6.35mm
Switch Operation:	On-Off-On
Terminal Type:	Solder

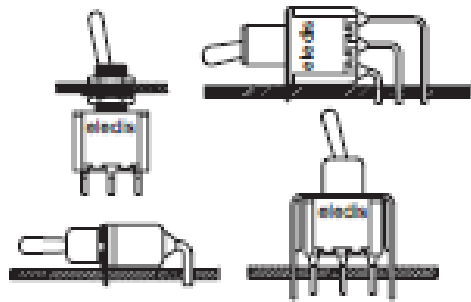

DPDT			
1	on	none	on
2	on	none	(on)
3	on	off	on
4	(on)	off	(on)
5	on	off	(on)
6 (*)	on	on	on
	2-3, 5-6 open		2-1,5-4

