

ToLEDo G9/G4/Pygmy

ToLEDo Pygmy 1.5W 60LM 830 E14 SL

0026510



Range features

- Up to 80% energy saving compared to halogen lamps
- 100% retrofit - compact size for existing fittings
- Uniform light distribution
- Available in Homelight (2700K) and Warm White (3000K)
- Average rated life up to 25,000 hrs
- ToLEDo Pygmy - ideal for use in refrigerators



PRODUCT OVERVIEW

Ordering number	0026510
Technology	LED
Light colour	830 warm white
Energy class	A+
Average life (Rated) (h)	15000
Lamp shape	Pygmy
Lamp finish	Frosted
Dimmable	No
Cap/Base	E14
Type	ToLEDo Pygmy/ G9/ G4
EAN code	5410288265100
CRI (Ra)	80
Colour temperature (K)	3000
Luminous flux (Rated) (lm)	60
Efficacy (Rated) (lm/w)	40
Watt (Nominal) (W)	1.5
Equivalent watt (W)	15
Voltage (V)	220-240

ToLEDo G9/G4/Pygmy

*ToLEDo Pygmy 1.5W 60LM 830 E14 SL***0026510****DATA TABLE**

General data

Ordering number	0026510
Dry applications use only	No
Technology	LED
Energy saving lamp	Yes
Average life (Nominal) (h)	15000
Energy class	A+
Average life (Rated) (h)	15000
Lamp shape	Pygmy
Lamp finish	Frosted
Dimmable	No
Cap/Base	E14
Type	ToLEDo Pygmy/ G9/ G4
EAN code	5410288265100
E-number FI	4740026
E-number SE	8359428
Long description	Up to 80% energy saving compared to halogen lamps. 100% retrofit - compact size for existing fittings. Uniform light distribution. Available in Homelight (2700K) and Warm White (3000K). Average rated life up to 25,000 hrs. ToLEDo Pygmy - ideal for use in refrigerators
Product name	ToLEDo Pygmy 1.5W 60LM 830 E14 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Fixture rating	Open
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	>7500
Special purpose lamp	No
Transformer required	No
Sales pack quantity	6
Optimal operating condition (°C)	25

ToLEDo G9/G4/Pygmy

ToLEDo Pygmy 1.5W 60LM 830 E14 SL

0026510

Optical data

Light colour	830 warm white
CRI (Ra)	80
Suitable for accent lighting	No
Colour temperature (K)	3000
Luminous flux (Rated) (lm)	60
Luminous flux (Nominal) (lm)	60
Lumen maintenance at end of nominal life (%)	70
Chromaticity coordinate Y	-1
Chromaticity coordinate X	-1
Adjustable chromaticity	No

Electrical data

kWh per 1000 hours burning time	2
Efficacy (Rated) (lm/w)	40
Watt (Rated) (W)	1.5
Watt (Nominal) (W)	1.5
Equivalent watt (W)	15
Voltage (V)	220-240
Lamp power factor	0.3

Physical data



Weight (kg)	0.02
Lamp Length (mm) - C/L	60
Max. Lamp Diameter (mm) - D	27
Lamp dimension equal to filament lamp equivalent	Yes
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	7.30 x 4.80 x 4.80
Inner package dimensions (L x W x H) (cm)	19.40 x 14.10 x 10.80
Inner package net weight (kg)	0.10
Outer package dimensions (L x W x H) (cm)	74.50 x 21.00 x 24.80

ToLEDo G9/G4/Pygmy

ToLEDo Pygmy 1.5W 60LM 830 E14 SL

0026510

TECHNICAL DRAWINGS

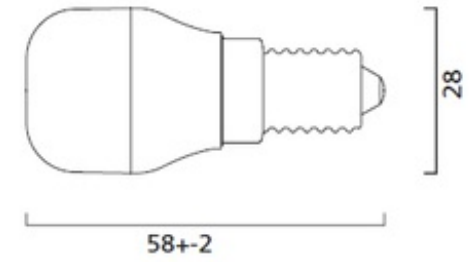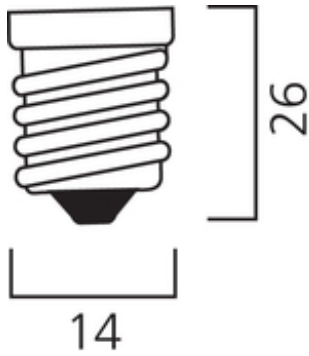

Dimensions (mm)

ENERGY LABEL

□