

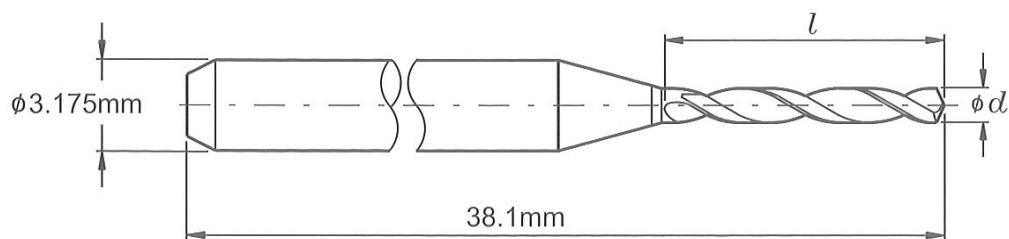
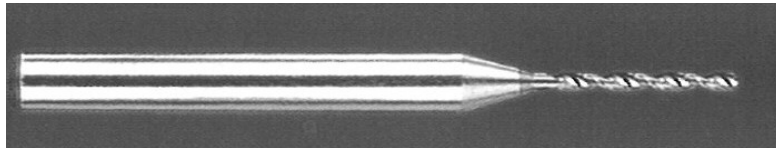


www.cif.fr

Carbide tungsten drill
Set of 10 bits
Diameter 2 mm
DU80.10

This document contains manufacturer's information, protected through copyright. All rights reserved. This document can not be copied, reproduced or translated without written agreement from **C.I.F**

Information contained in this document can be modified without any prior notice

CHARACTERISTICS**Carbure tungsten drill bit**

- Monopiece. Queue reinforced 3,17
- Diameter : 2 mm
- Minimum drilling speed 20 000 tr/min
- Most little is the diameter, higher will be the speed
- Descent speed from 1,6 to 4 m/min
- Option, drill bits with ring

UTILISATION

General use for drilling on different type of PCB support such as epoxy (typical use), EMC-1, EMC-3, etc..

cif@cif.fr