

#4135 - 2 Core Flat Loudspeaker Cable 4.0mm², 100m reel



Part NO: #4135

Product Code: RGW-1882

Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

2Cores

Cable Construction

Conductor **Bare Copper**
 Construction $0.1 \pm 0.008 \times 73 \times 7$
 Standard Dia.(mm) 3.02

Insulation **Trans PVC**
 Thickness 1.0
 Insulation Dia.(mm) $5.0 \pm 0.1 \times 2C$
 Insulation Color Trans PVC

Marking

Colour Stripe (Black) on one side for identification


PACKAGING

100M/Reel

Revision History

A0-1

Design

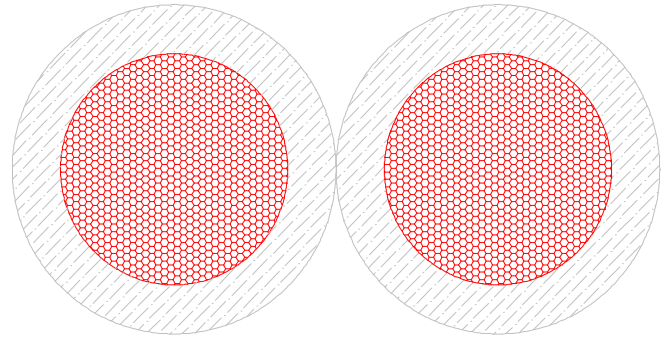

A: Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km) <4.64
 Min.Insulation DC Resistance at 20°C (MΩ *Km) >200
 Rated Temperature(°C) 80
 Rated Voltage (V) 300

RoHS GUIDELINE

We operate according to the following standards

Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls(PBB)	Forbidden	GC/MS	
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	

Date: 2013-03-06

Page: 1 / 1