


Busch-Blind control II

Inserts for flush-mounted devices

Busch-Blind control II switch insert

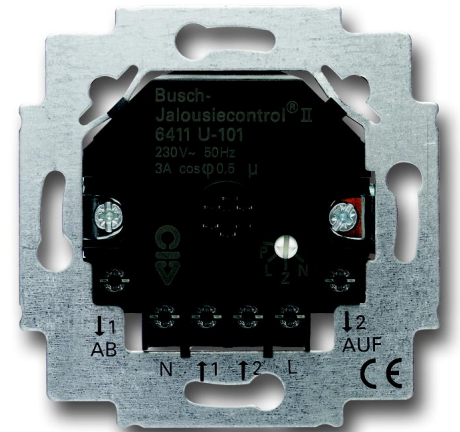

Suitable for blind, roller blind and awning drives with mechanical or electronic limit switch shut-off.

With two 230 V multi-way input terminals (Up/Down) for group control.

With operating mode switch for the following modes: normal, louvre, base station, position.

With party function (disables the local control unit) in combination with Busch-Blind control II control cover 6430-xx-xxx, 6066-xx-xxx.

Wind alarm, cleaning functions can be accommodated via extension input.

For control cover 6430-xx-xxx.

For IR control element 6066-xx-xxx.

For comfort timer control element 6455.

Running time: 3 min

Rated voltage: 230 V~, +10 % / -10 %, Rated frequency: 50 Hz - 60 Hz,

Outputs: 2 Normally open contact, Rated current: 3 A, cos phi 0.5, Rated power: 690 VA, Control/Signal outputs: 2,

Temperature range (Device): 0 °C to 35 °C,

Suitable for multi-phase operation., Compatible with types 6411 U/x.

Order Code : 6410-0-0377

Article No. : 6411 U-101

EAN: 4011395076484