


120


ISO A1/45°
45° Elbow

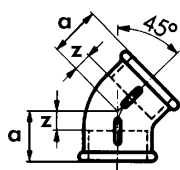

Dimension	Code	a	z
• S $\frac{3}{8}$	770 120 103	20	10
• V $\frac{3}{8}$	770 120 203		
• S $\frac{1}{2}$	770 120 104	22	9
• V $\frac{1}{2}$	770 120 204		
• S $\frac{3}{4}$	770 120 105	25	10
• V $\frac{3}{4}$	770 120 205		
• S 1	770 120 106	28	11
• V 1	770 120 206		
• S $1\frac{1}{4}$	770 120 107	33	14
• V $1\frac{1}{4}$	770 120 207		
• S $1\frac{1}{2}$	770 120 108	36	17
• V $1\frac{1}{2}$	770 120 208		
• S 2	770 120 109	43	19
• V 2	770 120 209		
• S $2\frac{1}{2}$	770 120 110	48	21
• V $2\frac{1}{2}$	770 120 210		
• S 3	770 120 111	54	24
• V 3	770 120 211		

121

ISO A4/45°
45° Elbow

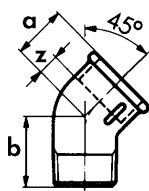

Dimension	Code	a	b	z
• S $\frac{3}{8}$	770 121 103	20	25	10
• V $\frac{3}{8}$	770 121 203			
• S $\frac{1}{2}$	770 121 104	22	28	9
• V $\frac{1}{2}$	770 121 204			
• S $\frac{3}{4}$	770 121 105	25	32	10
• V $\frac{3}{4}$	770 121 205			
• S 1	770 121 106	28	37	11
• V 1	770 121 206			
• S $1\frac{1}{4}$	770 121 107	33	43	14
• V $1\frac{1}{4}$	770 121 207			
• S $1\frac{1}{2}$	770 121 108	36	46	17
• V $1\frac{1}{2}$	770 121 208			
• S 2	770 121 109	43	55	19
• V 2	770 121 209			
• S $2\frac{1}{2}$	770 121 110	46	54	19
• V $2\frac{1}{2}$	770 121 210			
• S 3	770 121 111	52	61	22
• V 3	770 121 211			