

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130015-0112](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change® C-Size Receptacle with Leads 1/2" - 14 NPT Threads, Male (Straight) 19 Poles, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Receptacles
Series	130015
Comments	C-Size (1-1/8" - 16 UN-2A)
IP Rating	IP67
Overview	Brad® Mini-Change® Connectors
Product Name	Mini-Change®
Type	Single Ended (pigtail)
UPC	78678846667

Physical

Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	2.0m
Material - Component	Gray Anodized Aluminum
Mounting Thread Size	PG16
Net Weight	259.510/g
Orientation	Straight
Panel Mount	Back, Front
Poles	19
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	18, 22
Wire/Cable Type	N/A

Electrical

Current - Maximum per Contact	2A
Voltage - Maximum	300V AC/DC

Material Info

Old Part Number	3R3N36E80M020
-----------------	---------------

Reference - Drawing Numbers

Sales Drawing	SD-130015-009
---------------	---------------

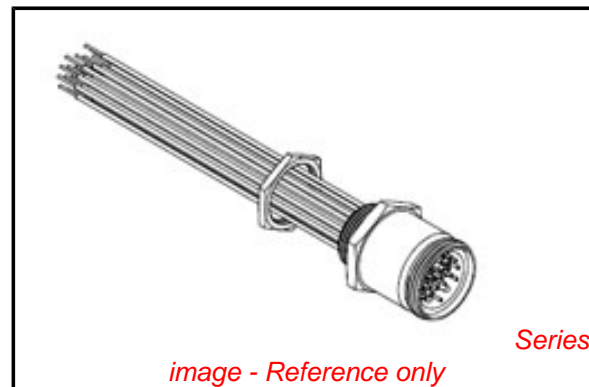


image - Reference only

EU RoHS

RoHS Compliant by Exemption
REACH SVHC Not Reviewed
Low-Halogen Status Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
 130015Series