

SAMSUNG

TURN ON TOMORROW

Samsung Colour Laser Printers CLP-320/320N and CLP-325/325W



Key Features:

- One Touch Print Screen button for immediate, on-screen printing¹
- One Touch Wi-Fi set up²
- Ultra Compact Footprint of 388mm x 313mm x 243mm (WxDxH)
- Fast Print Speeds of 4/16ppm (colour/mono)
- First Page Out Time of less than 14/26 seconds (colour/mono)
- Sharp Resolution at 2,400 x 600 dpi
- 130 sheet input capacity, 80 sheet output capacity
- Standard average cartridge yield of 1,500 pages for mono and 1,000 pages for colour

Compact, powerful and easy to use, the Samsung CLP-320 series includes advanced colour printers designed with high quality performance and usability in mind. Suitable for any home or small office, these colour laser printers deliver sharp, consistent printouts with durable text and graphics. User-friendly features, a variety of connectivity options, and a high quality output make it easy to create a lasting impression with colour prints. The CLP-320 series offers users additional benefits such as:


- **One-Touch Printing – See it, Print it!**: Samsung's unique one-touch Print Screen button is the quick and easy way to print the exact contents of your screen, without the usual format changes needed for printing content from sources such as web pages.
- **Polymerized Technology**: Samsung original Polymerized Toner is more uniform in particle size and shape which distributes more evenly than conventional toner. This technology produces sharper images and a wider colour range with glossier finishing, resulting in consistent, professional looking documents. With an overall CO₂ reduction of 35% during production, Polymerized Toner also has less impact on the environment.
- **Easy Installation and Management**: The front panel offers an easily accessible soft power button, for simple operation. The USB 2.0 interface means easy plug and play installation across all the latest operating systems – including Windows 7. Network and Wireless² options can be easily set up to support multiple users, immediately improving productivity and efficiency.

Top 3 Reasons to Buy:

- 1 Ease of Use:**
 - Easy plug and play installation that enables instant productivity
 - Simple operation with one-touch functionality for immediate access to convenient functions such as Print Screen¹ and Wi-Fi Set-Up²
 - Quickly switch to energy-saving standby mode with the easy to reach soft power button on the front panel
- 2 Innovative Design:**
 - Small and compact to fit neatly anywhere in your home or small office
 - Stylish in two-tone crema grey or matt piano black colour design options
- 3 Efficient Performance:**
 - Consistent durable output with no clogging and less mess
 - Toner consumables last longer with a high toner yield of 1,500 pages (mono) and 1,000 pages (colour)
 - Low power consumption of just 6W in Sleep Mode means lower energy costs and a reduced carbon footprint
 - Designed with NO-NOIS™ technology for quiet operation and reduced interference and vibration, minimising any unnecessary distractions³

¹CLP-320/325 only ²CLP-325W only ³CLP-325/325W only

Range Positioning:

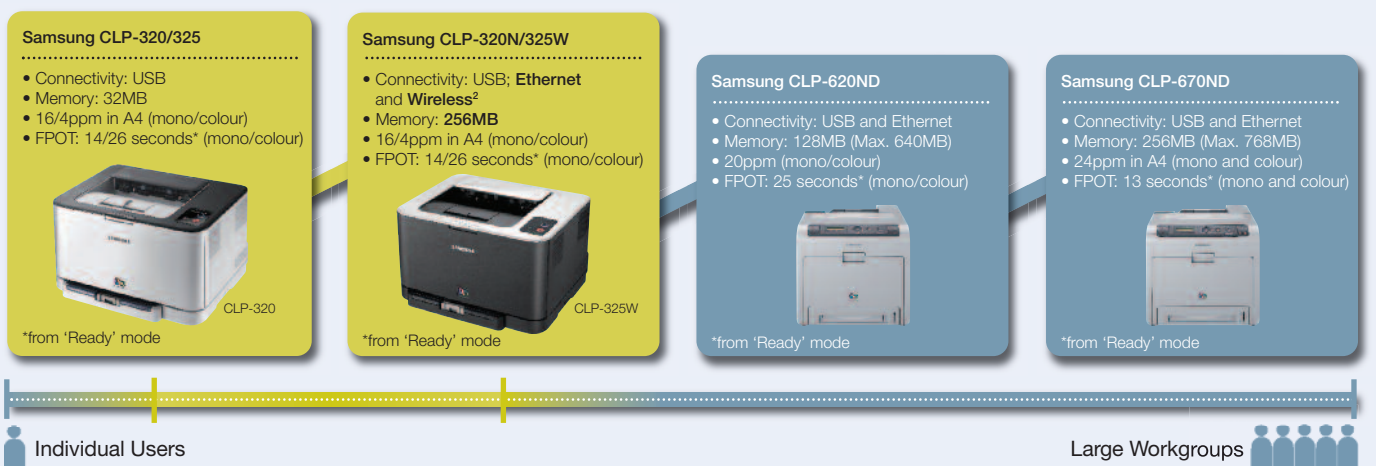

Product Datasheet

Printing solutions
as easy as



Product Specifications



Print	CLP-320	CLP-320N	CLP-325	CLP-325W
Speed	Up to 16/4ppm (mono/colour) in A4			
Resolution	Up to 2,400 x 600 dpi effective output (maximum); Up to 1,200 x 600 dpi effective output (default); Up to 600 x 600 dpi (draft)			
First Page Out Time	Less than 14/26 seconds (mono/colour) in A4			
Emulation	SPL-C (Samsung Printer Language Colour)	SPL-C (Samsung Printer Language Colour), PCL6	SPL-C (Samsung Printer Language Colour)	SPL-C (Samsung Printer Language Colour), PCL6
Paper Handling				
Input Capacity and Types	130-sheet Cassette @ 80gsm			
Output Capacity and Types	80 sheets @ 80gsm			
Media Sizes	76mm x 152.4mm ~ 216mm x 355.6mm			
Media Types	A4, A5, A6, Letter, Executive, Folio, ISO B5, JIS B5 Transparencies (mono print only), Glossy Photo160 g/m2, Envelope, Labels, Cardstock, Recycled, Pre-printed			
General				
Processor	360MHz			
Memory	32MB	256MB	32MB	256MB
OS Compatibility	Windows 2000/XP/2003/Vista/2008, Windows 7/2008 R2; Fedora 2~9 (32/64bit), openSuSE 9.1, 9.2, 9.3, 10.0, 10.1, 10.2, 10.3, 11.0 (32/64bit), Ubuntu 6.04, 6.10, 7.04, 7.10, 8.04 (32/64bit), Mandriva 10.0, 10.1, 2005, 2006, 2007, 2008 (32/64bit), Debian 3.1, 4.0 (32/64bit), Redhat Enterprise Linux WS 4, 5 (32/64bit), SuSE Linux Enterprise Desktop 9, 10 (32/64bit); Mac OS X 10.3~10.6 and Universal Mac			
Interface	USB	USB, Ethernet	USB	USB, Ethernet, Wireless (Wi-Fi Standard IEEE802.11 b/g/n)
Noise Level	Less than 45dBA (colour printing); Less than 47dBA (mono printing)			
Power Consumption	80W (Ready Mode)			
Maximum Monthly Duty Cycle	20,000 pages			
Dimension (W x D x H)	388mm x 313mm x 243mm			
Weight (including toner)	11kg			

Supplies:

Article No.	Description					
Model Code	CLT-K4072S/ELS	CLT-C4072S/ELS	CLT-Y4072S/ELS	CLT-M4072S/ELS	CLT-R407/SEE	CLT-W409/SEE
Description	Black Toner Cartridge	Cyan Toner Cartridge	Yellow Toner Cartridge	Magenta Toner Cartridge	OPC Drum	Waster Toner Bottle
Yield (ISO/IEC 19798)	1,500 pages	1,000 pages	1,000 pages	1,000 pages	24,000 pages	5,000 pages
Compatible Hardware Models	CLP-320, CLP-320N, CLP-325, CLP-325W, CLX-3185, CLX-3185N, CLX-3185FN, CLX-3185FX					
Item Box Dimensions (L x W x H)	183mm x 363mm x 73mm	183mm x 363mm x 73mm	183mm x 363mm x 73mm	183mm x 363mm x 73mm	174mm x 339mm x 298mm	119mm x 73mm x 170mm
Item Box Weight (Gross)	1.22kg	1.15kg	1.14kg	1.14kg	1.46kg	0.17kg
Items in Master Box	4	4	4	4	4	6
Master Box Dimensions (W x D x H)	465mm x 381mm x 309mm	465mm x 381mm x 309mm	465mm x 381mm x 309mm	465mm x 381mm x 309mm	624mm x 390mm x 362mm	255mm x 243mm x 197mm
Master Box Weight (Gross)	4.88kg	4.6kg	4.56kg	4.56kg	5.82kg	1.22kg

Visit: www.samsung.com/supplies



* CLP-320N/325W **CLP-325W

For more information, please visit www.samsung.com

Printing solutions
as easy as



TURN ON TOMORROW