


TT3 10-4-4

Isolating transformer

- Safety electrical isolation
- ± 5 % secondary tapings for easy adaption of the voltage
- Screw mounting

Isolating transformer to IEC 61558-2-4, DIN EN 61558-2-4,
VDE 0570 part 2-4

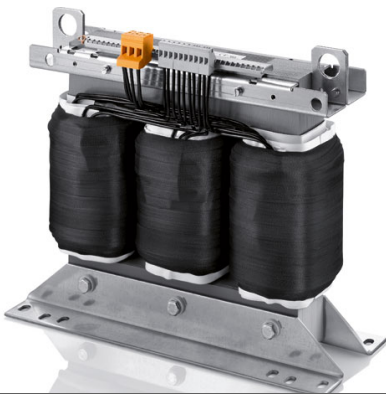

TT3 10-4-4

Isolating transformer



Input data	
Rated voltage	3 x 400 V
Short circuit voltage	≤3 %
Rated current	3 x 14,9 Aac
Frequency range	50 - 60 Hz
Output data	
Rated voltage	3 x 380 V; 3 x 400 V; 3 x 420 V
Rated current	3 x 15,1 Aac (3 x 380 V); 3 x 14,4 Aac (3 x 400 V); 3 x 13,8 Aac (3 x 420 V)
Power	10000 VA
Standards and security	
Protection index	IP 00
Safety class (prepared)	I
Ambient temperature max.	50 °C
Class of Insulation System	F
Test voltage	4800 V
General data	
Vector group	Dyn 5
Power loss	350.0 W
Mechanical data	
Type	open type
Core type	3UI 210/73
Terminals	screw type terminals
Fixing method	mounting brackets
Fixing screws	-
Dimensions W x H x D	480 x 400 x 192
Weight	87.00 kg

BLOCK Transformatoren-Elektronik GmbH

Max-Planck-Straße 36-46

27283 Verden

Germany

Phone +49 4231 678-0

Fax +49 4231 678-177