



Product Datasheet

ENGLISH

69m x 12mm Portable Manual Rewind Hose Reel



69m x 12mm Portable Manual Rewind Hose Reel

“Caddy Mount” hand crank hose reels offer lightweight, compact portability for long lengths of hose. Eliminate the task of manually coiling and uncoiling hose and easily transport it to the job site on wheels.

**Specification**

TYPE	
Manual & Motor	Hand Crank

HOSE	
I.D. (Inside Diameter)	12mm
Length(m)	69
Pressure(BAR)	280
No. of Hoses	1 - Single
Supplied with Hose	No

APPLICATIONS	
Media	Air or Water
Construction	Steel
Max Working Temp	99°C
Weight	13 kg


SWIVEL	
Material	Brass
Seals	Nitrile

CONNECTION	
Inlet	1/2"
Outlet	1/2"



Dimensions

ENGLISH

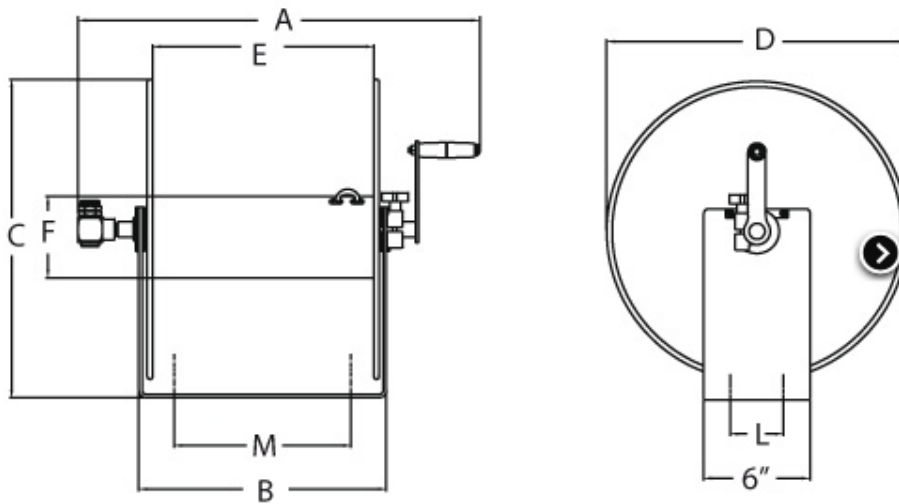

A	B	C	D	E	F	L	M
140	164	432	419	587	451	79	267

All dimensions are in mm