

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **502078-3910**  
**Status:** **Active**  
**Overview:** FFC-FPC (SMT)  
**Description:** 0.25mm Pitch Easy-On™ Type FPC Connector, 1.00mm Mated Height, Right Angle, Surface Mount, Bottom Contact Style, 39 Circuits, Halogen-Free

**Documents:**

[3D Model](#) [Packaging Specification SPK-502078-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-502078-002 \(PDF\)](#)

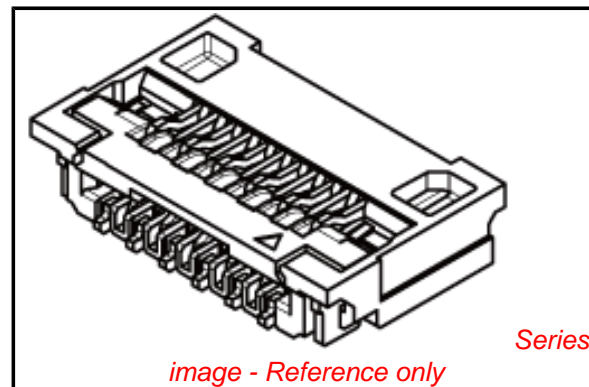


image - Reference only

**General**

Product Family	FFC/FPC Connectors
Series	502078
Overview	<u>FFC-FPC (SMT)</u>
Product Name	Easy-On™
UPC	883906193676

**Physical**

Circuits (Loaded)	39
Contact Position	Bottom
Durability (mating cycles max)	10
Entry Angle	90° Angle
Mated Height	1.00mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	55.890/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.25mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-20°C to +85°C
Termination Interface: Style	Surface Mount
Wire/Cable Type	FPC only

**Electrical**

Current - Maximum per Contact	0.2A
Voltage - Maximum	50V

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	SPK-502078-001
Product Specification	PS-502078-002, RPS-502078-005, RPS-502078-006, RPS-502078-007, RPS-502078-012
Sales Drawing	SD-502078-003, SD-502078-004

**EU RoHS**

**ELV and RoHS  
Compliant**  
**REACH SVHC  
Contains SVHC: No**  
**Low-Halogen Status  
Low-Halogen**

**China RoHS**



**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

502078Series