

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19164-0015](#)
Status: **Active**
Overview: [Perma-Seal™ Terminals](#)
Description: Perma-Seal™ Male Quick Disconnect Tab for 18-22 AWG Wire, Tab Size 6.35 x 0.81mm

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E79133

General

Product Family Quick Disconnects
 Series [19164](#)
 Crimp Quality Equipment Yes
 Insulated No
 Overview [Perma-Seal™ Terminals](#)
 Product Name Perma-Seal™
 Type Quick Disconnect
 UPC 800753113039

Physical

Barrel Type Closed
 Color - Resin Red
 Gender Male
 Glow-Wire Compliant No
 Insulation NiAc™
 Lock to Mating Part None
 Material - Metal Brass
 Material - Plating Mating Zinc Chromate
 Material - Plating Termination Zinc Chromate
 Material - Resin Nylon
 Net Weight 1.633/g
 Orientation Straight
 Packaging Type Bag
 Plating min - Mating 5.080µm
 Plating min - Termination 5.080µm
 Tab Thickness 0.81mm
 Tab Width 6.35mm
 Temperature Range - Operating -55°C to +125°C
 Wire Insulation Diameter 3.81mm max.
 Wire Size AWG 18, 20, 22
 Wire Size mm² 0.25 - 1.50

Electrical


Voltage - Maximum 600V

Material Info

Old Part Number SAA-9260

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013
 Sales Drawing SD-19164-039

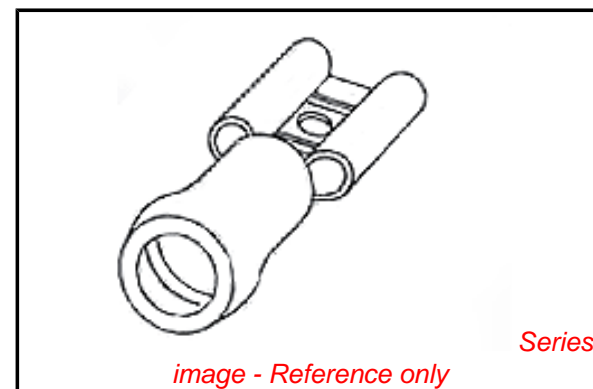

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[19164Series](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

| Description | Product # |
|--|----------------------------|
| Crimp Head for the AT-200™ Pneumatic Hand Tool | 0640054500 |
| Crimp Head for the AT-200™ Pneumatic Hand Tool | 0640054700 |
| Hand Crimp Tool PremiumGrade™ | 0640014700 |
| Hand Crimp Tool | 0640014500 |

This document was generated on 10/02/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION