

# GEL-GRIP

## ADVANCED TAPE TECHNOLOGY

FORTSCHRITTLICHE TECHNIK  
MÈTRES À RUBAN TECHNOLOGIQUEMENT ÉVOLUÉS  
TECNOLOGÍA AVANZADA DE CINTAS




**1 Gel-grip jacket provides exceptional comfort with outstanding damage protection**

Gel-grip Gehäuse bietet außergewöhnlichen Komfort mit überragendem Beschädigungsschutz  
Corps en gel procure un confort exceptionnel avec une protection remarquable contre les chocs  
La carcasa Gel-grip proporciona un confort excepcional con protección excelente contra daños

**2 Specially designed end hook grips on the top, bottom & side**

Speziell entworfener Endhaken greift oben, unten und seitlich  
Crochet d'extrémité spécialement conçu s'accroche sur le dessus, au-dessous et sur le côté  
Cuenta con gancho especialmente diseñado para enganchar por la parte superior, inferior y lateral

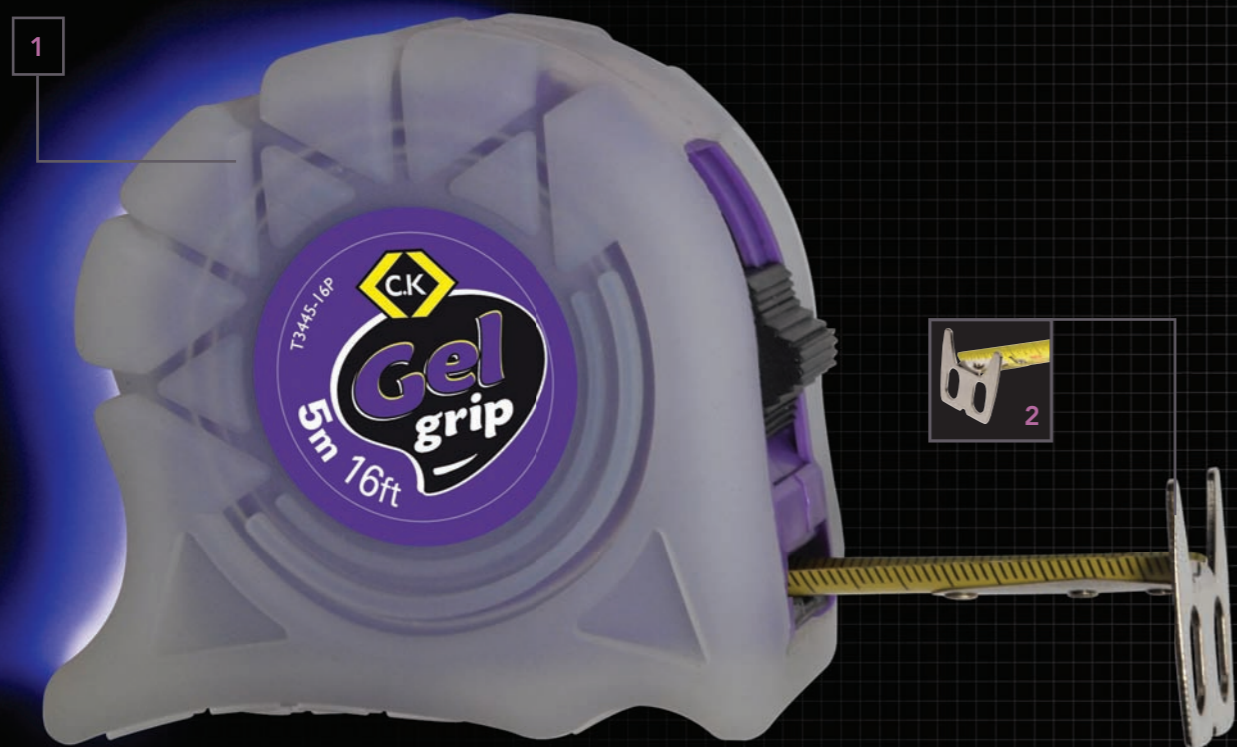

### OVERHEAD MEASURING

ÜBERKOPF MESSEN  
MESURAGE EN SURPLOMB  
MEDICIÓN ELEVADA



### VERTICAL MEASURING

VERTIKAL MESSEN  
MESURAGE VERTICAL  
MEDICIÓN VERTICAL



### SIDE MEASURING

SEITLICH MESSEN  
MESURAGE SUR LE CÔTÉ  
MEDICIÓN LATERAL




# DEVELOPED SPECIFICALLY FOR THE PROFESSIONAL TRADESMAN, THE C.K GEL-GRIP TAPE ENCOMPASSES THE VERY LATEST IN TAPE TECHNOLOGY

SPEZIFISCH FÜR DEN FACHMANN ENTWICKELT, UMFASST C.K GEL-GRIP DIE NEUESTEN TECHNOLOGIEN

SPÉCIFIQUEMENT ÉLABORÉ POUR LES UTILISATEURS PROFESSIONNELS, LE MÈTRE À RUBAN C.K GEL-GRIP INTÈGRE LES TOUTES DERNIÈRES ÉVOLUTIONS DE LA TECHNOLOGIE DES MÈTRES À RUBAN

DESARROLLADA ESPECÍFICAMENTE PARA LOS PROFESIONALES DEL SECTOR, LA CINTA C.K GEL-GRIP INCLUYE LO ÚLTIMO EN LA TECNOLOGÍA DE FLEXÓMETROS

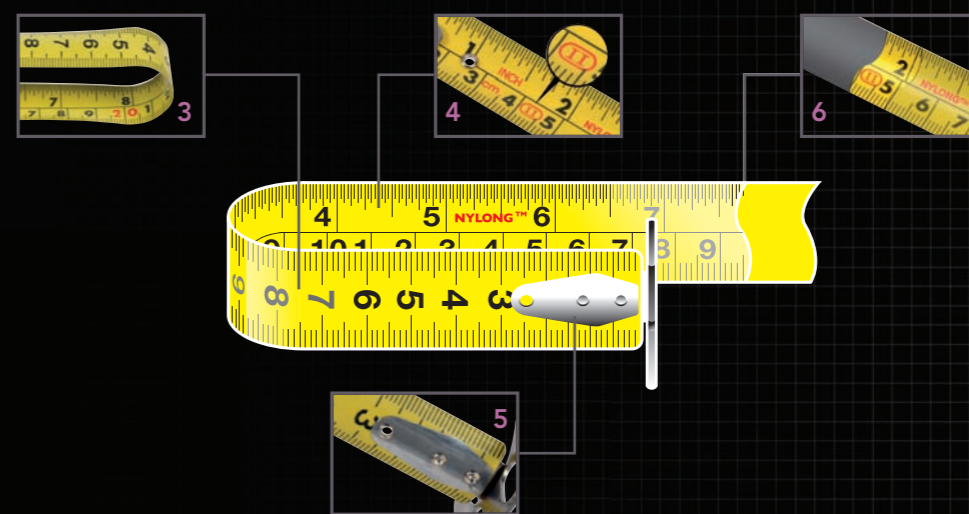

**3 Double sided marking for regular, overhead & vertical measuring**

Doppelseitige Markierung für normales, horizontal überkopf und vertikales Messen  
Marquage sur les deux faces pour les relevés de cotes classiques, en surplomb et verticaux  
Marcado en ambos lados para conseguir mediciones normales, elevadas y verticales

**4 EC Class II for greater measuring accuracy (accurate to 1mm over 3m)**

EC Klasse II für höhere Messgenauigkeit (1 mm über 3 m)  
CE classe II pour une plus grande exactitude de mesurage (précision de 1 mm sur 3 m)  
EC Clase II para una mayor exactitud de medición (precisión en 3m de 1 mm)

**5 Triple riveted hook prevents blade & hook damage on rewind**

Dreifach vernieteter Haken vermeidet Band- und Hakenbeschädigungen beim Zurückspulen  
Le triple rivetage du crochet empêche toute détérioration au rebobinage  
El gancho con triple remachado previene el daño producido en hoja y gancho durante el rebobinado

**6 NYLON™ coated blade for superior abrasion resistance & durability**

NYLON™-beschichtetes Band - überragend abriebresistent und hohe Dauerhaftigkeit  
Ruban à revêtement NYLON™ garantissant une excellente résistance à l'abrasion et une longue durabilité  
Cinta con recubrimiento NYLON™ para una resistencia superior a la abrasión y una mayor durabilidad

LACQUERED  
LACKIERT  
LAQUÉ  
LACADA

NYLON™



**Results of a stringent 15 litre sand blast test.**

Ergebnis eines stringenten 15 Liter Sandblastest.  
Résultats d'un essai rigoureux de sablage à 15 litres.  
Resultados conseguidos mediante una rigurosa prueba con 15 litros de chorro de arena.

## GEL-GRIP

- Fully featured tape measure - see previous feature page



### Gel-grip tapes - 5m / 16ft

2004/22/EC Class 2

Item Number		i	
T3445-16B	19mm	blue	6
T3445-16G	19mm	green	6
T3445-16O	19mm	orange	6
T3445-16P	19mm	purple	6
T3445-16R	19mm	red	6



### Gel-grip tape - 7.5m / 25ft

2004/22/EC Class 2

Item Number		i	
T3445-25	25mm	orange	6

CONTENTS: 4 x blue, orange & green Gel-grip tapes, size 5m/16ft.



### Gel-grip tapes display

2004/22/EC Class 2

Item Number		i	
T3445-16-CBOX	stock & display		1

CONTENTS: 4 x blue, orange & green Gel-grip tapes, size 5m/16ft.

### Gel-grip tapes display refill pack

2004/22/EC Class 2

Item Number		i	
T3445-16-RFIL	stock only		1

## TAPE MEASURES

- Tough ABS plastic body for damage protection
- Full lock & pause buttons for control
- Belt clip for convenience
- NYLONG™ coated blade for superior abrasion resistance & durability
- 16" & 400mm joist centre markings for fast marking out
- True zero hook for accurate external & internal measurements
- Integral recoil damper for hook damage protection




### ST tape measures

2004/22/EC Class 2

Item Number		i	
T3442 10	3m 10ft	metric/imperial	6
T3442 16	5m 16ft	metric/imperial	6
T3442 25	7.5m 25ft	metric/imperial	6
T3442M 3	3m	metric	6
T3442M 5	5m	metric	6
T3442M 8	8m	metric	6

- Tough steel case for damage protection
- Fold out blade hook for secure anchoring
- Hand strap for convenient carrying
- Fold out winding handle for rapid rewind & safe storage
- Nylon coated steel tape - extremely strong & stretch resistant
- Double sided metric/imperial graduations

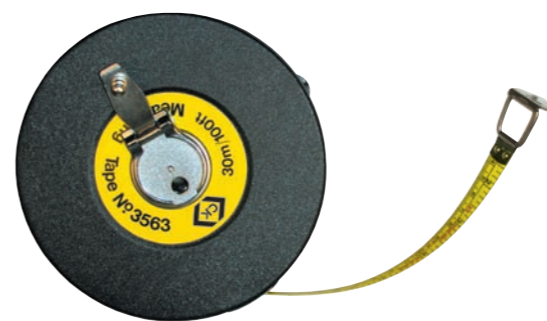

### Measuring tape - Steel

2004/22/EC Class 3

Item Number			
T3563 100	30m 100ft	13mm 1/2"	3

- Tough ABS plastic body for damage protection
- Fold out blade hook for secure anchoring
- Hand strap for convenient carrying
- Fold out winding handle for rapid rewind & safe storage
- Glassfibre reinforced tape - strong & stretch resistant
- Double sided metric/imperial graduations



### Measuring tape - Fibreglass

2004/22/EC Class 3

Item Number			
T3561 100	30m 100ft	13mm 1/2"	3

- Tough ABS plastic body for damage protection
- Integral ground spike & fold out blade hook for secure anchoring
- Soft grip handle for comfortable carrying
- Fold out winding handle for rapid rewind & safe storage
- Glassfibre reinforced tape - strong & stretch resistant
- Double sided metric/imperial graduations



### Surveyor's tapes

2004/22/EC Class 3

Item Number			
T3565 100	30m 100ft	13mm 1/2"	3
T3565 165	50m 165ft	13mm 1/2"	3
T3565 330	100m 330ft	13mm 1/2"	3

## RULES

- Stainless steel for corrosion protection
- Permanent indented markings for wear resistance
- Fine graduations for accurate measurements



### Steel rules - Metric/imperial

Item Number	Length	Thickness	Pack
T3530 06	150mm 6"	18mm	6
T3530 12	300mm 12"	25mm	6

- High quality construction with brass hinges & end caps for durability
- Four fold design for compact storage
- Permanent indented markings for wear resistance



### Wooden rule - Metric/imperial

Item Number	Length	Pack
T3510	1m 3ft	6

- Anodised aluminium construction with a strong plastic handle - lightweight, easy clean
- Metric graduations
- Ideal for cutting, measuring and marking out



### Straight edge/rule

Item Number	Length	Pack
T3531 100	1000mm 40"	1

## SPIRIT LEVELS

- Powder coated, box section aluminium - strong, light & durable
- Shockproof, unbreakable vials, guaranteed leakproof for three years
- Luminous horizontal vial for low light conditions
- Precision manufactured, accurate to +/- 0.5mm per metre
- Metric measurement graduations for convenience
- 16" (400mm) & 24" (600mm) feature 1 vertical & 1 horizontal vial
- 32" (800mm) and above feature 2 vertical & 1 horizontal vials



### Aluminium box levels

Item Number	Length	Vials	Pack
T3494 16	400mm 16"	2 vial with rule	1
T3494 24	600mm 24"	2 vial with rule	1
T3494 32	800mm 32"	3 vial with rule	1
T3494 40	1000mm 40"	3 vial with rule	1
T3494 48	1200mm 48"	3 vial	1
T3494 70	1800mm 70"	3 vial	1

- Tough ABS plastic body for damage protection
- V-groove base for pipework
- Magnetic base for steelwork
- Patented detachable mini level with magnetic base, ideal for setting patress boxes
- Also features string slots for use as line level
- 1 vertical & 1 horizontal vial



### Pocket level

Item Number	Length	Pack
T3482	210mm 8 1/4"	5

## CHALK, LINES & ACCESSORIES

- Die cast aluminium construction - strong & lightweight
- Fold away winding handle for convenient storage
- Self chalking line with end attachment hook for ease of use
- Supplied with 60g of blue chalk



### Chalk line reel & chalk - Heavy duty

Item Number	Length	Pack
T3520A	30m 100ft	6

- Tough plastic construction - strong & lightweight
- Fold away winding handle for convenient storage
- Self chalking line with end attachment hook for ease of use
- Supplied with 60g of blue chalk



### Chalk line reel & chalk

Item Number	Length	Pack
T3522	30m 100ft	6

- Strong & absorbent cotton for effective retention of marking chalk



### Chalk line - Cotton

Item Number	Length	Pack
T3517	18m 60ft	12

- Braided nylon construction - extra strong & durable



### Chalk line - Nylon

Item Number	Length	Pack
T3519	18m 60ft	12

- High density chalk for clear marking results
- Plastic refill container with re-sealable dispenser cap



### Chalk powders

Item Number	Weight	Color	Pack
T3521B 100	100g 4oz	blue	6
T3521R 100	100g 4oz	red	6

- Forged steel nickel plated for strength & corrosion resistance
- Suitable for use in wet & dry mortar



### Line pins

Item Number	Length	Quantity	Pack
T3490	170mm 6 1/2"	set of 2	10

- Conical, fully polished bob complete with screwed brass cord fitting



### Plumb bob

Item Number	Weight	Pack
T3492 11	300g 11oz	3

## JOINER'S SQUARES & BEVELS

- Hardened & tempered blued steel blade for corrosion resistance
- Blade secured with three brass rivets & brass inside face for long term accuracy
- Hard rosewood stock



### Joiner's squares - Rosewood

Item Number	Length	Quantity
T3540 09	225mm 9"	3
T3540 12	300mm 12"	3

- Hardened & tempered blued steel blade for corrosion resistance
- Quick lock lever for convenient adjustment
- Hard rosewood stock



### Sliding bevel - Rosewood

Item Number	Length	Quantity
T3541 9	225mm 9"	4

- Screw pin adjustment for accurate & consistent setting of mortice & tenon joints
- Heavy brass inlays on marking faces for protection
- Hard rosewood body



### Marking & mortice gauge - Rosewood

Item Number	Length	Quantity
T3543	190mm 7½"	1


- Hardened & tempered blued steel blade for corrosion resistance
- Blade secured with three brass rivets & brass inside face for long term accuracy
- Beech stock



### Joiner's square - Beech

Item Number	Length	Quantity
T3533 09	225mm 9"	3

- Hardened & tempered blued steel blade for corrosion resistance
- Beechwood stock

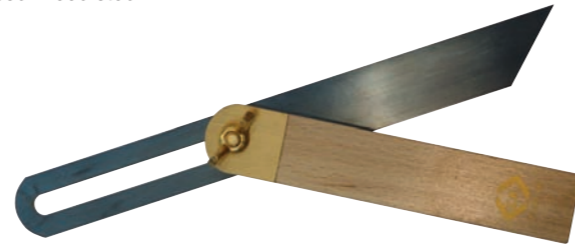

### Sliding bevel - Beech

Item Number	Length	Quantity
T3537 09	230mm 9"	3

- Thumbscrew adjustment for accurate & consistent marking
- Brass inlays on marking faces for protection
- Beechwood body



### Marking gauge - Beech

Item Number	Length	Quantity
T3542A	240mm 9½"	3

- Traditional rectangular leaded carpenters pencil




### Carpenter's pencil

Item Number	Quantity
T1125 24	72

## COMBINATION SQUARES

- Stainless steel rule for corrosion protection
- Permanent indented markings for wear resistance


- Heavy duty, 3 in 1 construction for a complete marking & measuring solution

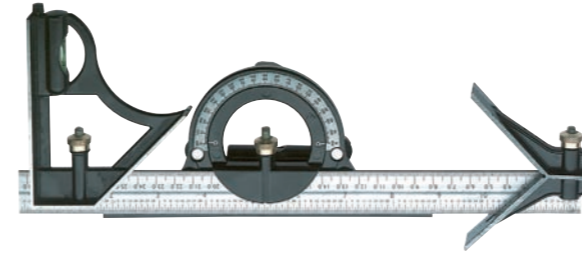

### Combination square - 3 in 1


Item Number	Length	Scale	Quantity
T3579	300mm 12"	metric/imperial	1

- Heavy duty construction for strength & durability

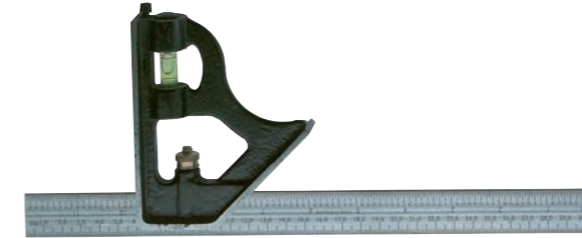

### Combination square - Heavy duty


Item Number	Length	Scale	Quantity
T3581	300mm 12"	metric/imperial	3

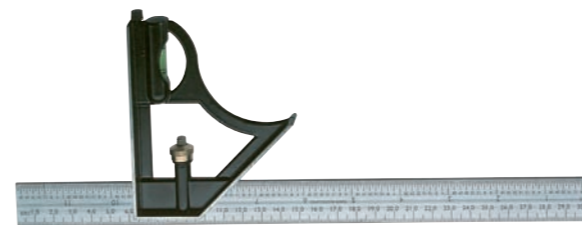

### Combination square

Item Number	Length	Scale	Quantity
T3582	300mm 12"	metric/imperial	3

- Roller adjustment along metric & imperial graduated rule for convenience
- Nickel plated for corrosion protection

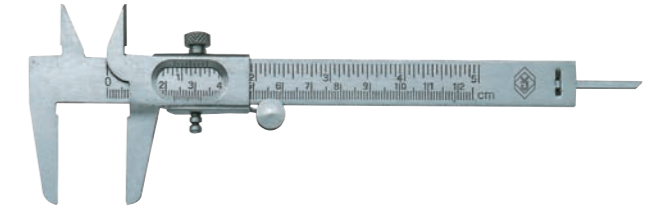

### Vernier caliper

Item Number	Length	Scale	Quantity
T3451	125mm 5"	metric/imperial	6

- Blades permanently etched with its size for long term use

CONTENTS (T3525 413): Imperial blades, sizes: 2, 3, 4, 5, 6, 8, 10, 12, 15, 20, 25, 30 & 35 thousandths of an inch.

 
CONTENTS (T3525M 413): Metric blades, sizes: 0.05, 0.10, 0.15, 0.20, 0.25, 0.30, 0.40, 0.50, 0.60, 0.70, 0.80, 0.90 & 1.00mm.



### Feeler gauges

Item Number	Length	Scale	Quantity
T3525 413	100mm 4"	imperial	3
T3525M 413	100mm 4"	metric	3

- Brass scale, black lacquered body, tinned hook & ring for corrosion resistance
- Calibrated in 1lb/0.5kg divisions



### Pocket balances

Item Number	Weight	Quantity
T6202 025	12.5kg 25lb	12
T6202 032	15kg 32lb	12
T6202 044	20kg 44lb	12
T6202 050	23kg 50lb	6
T6202 066	30kg 66lb	6
T6202 088	40kg 88lb	6
T6202 112	50kg 112lb	6