



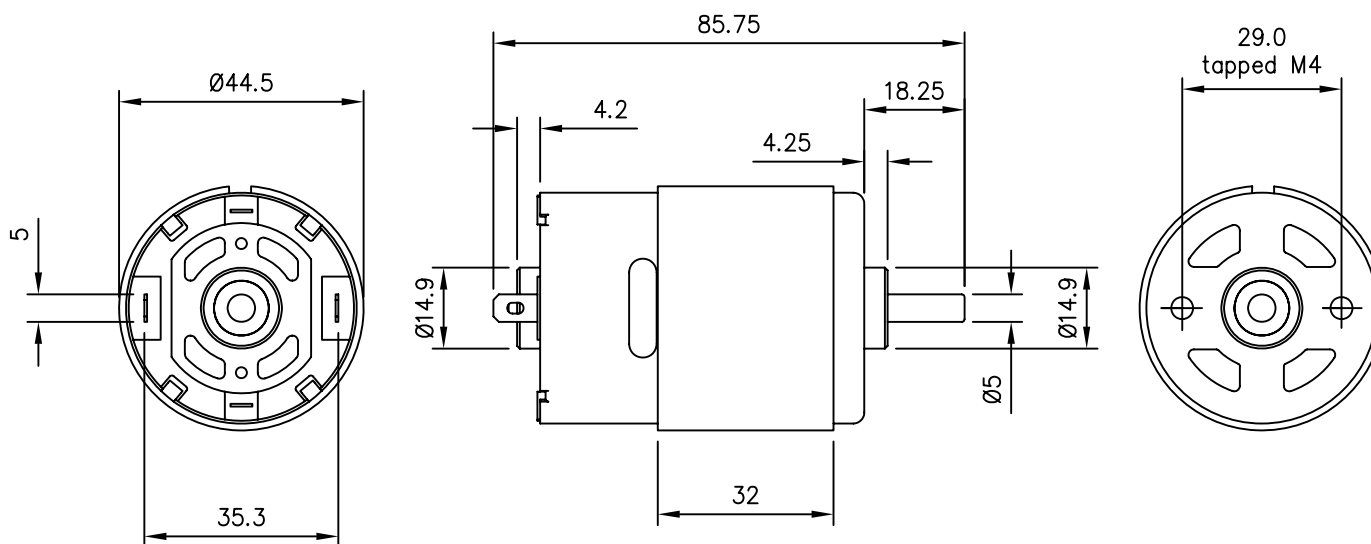

LABEL DETAILS

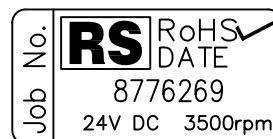

TECHNICAL DATA

Motor Type – 7 Series
Voltage – 24v DC

NO LOAD

SPEED – 3500rpm
CURRENT – 0.22Amps (0.31Amps max.)

AT MAX. EFFICIENCY

OUTPUT POWER – 13.6Watts
SPEED – 2840rpm
CURRENT – 0.95Amps (1.33Amps max.)
TORQUE – 468gf.cm

AT MAX. POWER

SPEED – 1750rpm
CURRENT – 2.16Amps (3.02Amps max.)
OUTPUT TORQUE – 1241gf.cm

STALL TORQUE – 2482gf.cm

Dimensions in mm

MELLOR ELECTRICS Ltd
BLACKBURN ENGLAND

DESCRIPTION	7 Series Motor 24v DC	DRAWN	LC	10/06/09
CUSTOMER	RS COMPONENTS	PART No	DC-1024	