 



## Product

### Abox 025 AB-2,5<sup>2</sup>

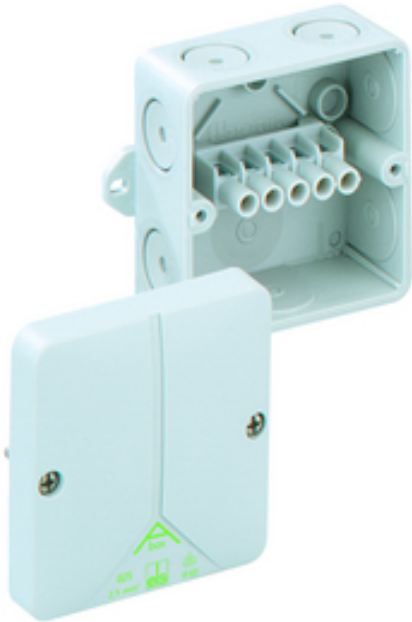

Junction box acc. DIN EN 60670 (VDE 0606),  $U_i=690V$ , with self-sealing, soft inlet membranes, M20, seal range 2 - 16 mm, with external fixing lugs

grey, with screw terminals 5-poles -  $2.5\text{ mm}^2$  ( $4 \times 1.5^2 / 4 \times 2.5^2$ )

**Article:** Abox 025 AB-2,5<sup>2</sup>

## Technical Data

### Dimensions:

Width: 80 mm  
 Length: 80 mm  
 Height: 52 mm

### material:

Base: {Polystyrol, Membranen aus TPE}  
 Cover: Polystyrene

### Properties:

Weatherproof: -  
 Ambient temperature (min.): -25 °C  
 Ambient temperature (max.): 40 °C  
 Ambient temperature (24 h): 35 °C  
 Max. rel. humidity at 40° C: 50%  
 Impact resistance: IK07 acc. DIN EN 5012 / VDE 0470 Part 100  
 Protection class: II - isolate protection acc. VDE 0106



