


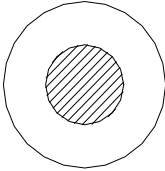

Product Name:	MIL-W-22759/9 26AWG
Product Discription:	MIL-W-22759/9 26AWG
Specification No.:	
Customer's Name:	

Description				
Rated Voltage:		1000V		
Rated Temperature:		200℃		
Reference Standard:		MIL-W-22759/9		
Cross Section				
				
Marking				
No marking on the cable jacket				
Applications				
These wires are ideal for internal wiring of appliances, electronic equipment and other applications.				
Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Danniel	Jason	19/05/2015
Construction				
Conductor		Stranded Sliver plated copper		
Size(AWG)		26		
Construction(±0.008mm)		19/0.10		
Stranded Dia.(mm)Ref.		0.5		
Insulation Material		PTFE		
Insulation Color		ANY COLOR		
Ave Thickness(mm)		0.38		
Insulation Dia.(±0.08mm)		1.26		
Remark: 8776140 Red 8776146 Blue 8776134 Black 8776159 White 8776143 Brown				
Characteristics				Customer Approve
Test Item		Standard Value		Seal & Stamp
Test Material		PTFE(ROHS)		
Insulation resistance(20℃ MΩ*m		1000		
Vol. Tesr(AC.V.60S) (V)		2000		
Flammability Test		VW-1		
Max.DC Resistance(20℃ Ω/km)		122.37(MAX)		
Signature:				
Date:				