


Datasheet

Surface Mount Buzzer

RS Stock number [780-0737](#)

Dimensions(mm):

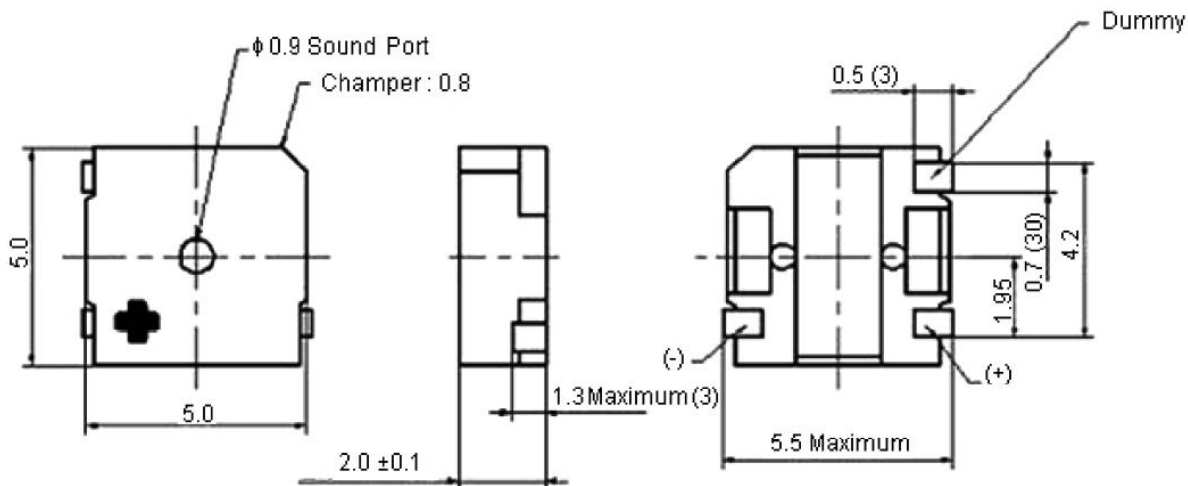

SPECIFICATIONS	Surface Mount Piezo Transducer
Rated Voltage (square wave)	3Vp-p
Operating Voltage	2-4Vp-p
*Rated Current (Max)	100mA
*Min Sound Output at 10cm, at 4 KHz	72dB
*Resonant Frequency	4000±500Hz
Operating Temperature	-30 ~ +70 °C
Storage Temperature	-40 ~ +85 °C
Weight	0.3g
Tone	Continuous
Drive Type	External

*Value Applying at Rated Voltage

Features:

- Colour: Black
- Ultra miniature surface mount device
- Sound emission from the top
- Requires additional electronic circuitry to operate as a sounder.

All data at 25°C unless otherwise specified.