

SC-SMT 3.81/./180G Tape




Dimensioned drawing

SC-SMT 3.81/./180LF Box



Dimensioned drawing

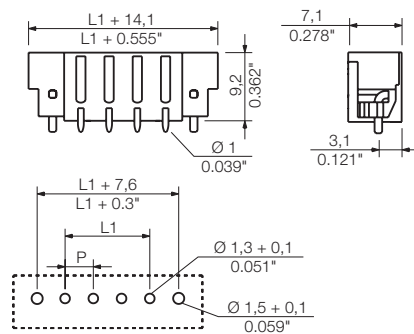

SC-SMT 3.81/./180LF Tape



Dimensioned drawing

Ordering data

Solder pin length		1.5 mm	3.2 mm
Colour		black	black
Pitch		3.81 mm	
Pol.	L1 (inch)	Qty.	Order No.
2	3.81 0.150	300	1864050000 1863450000
3	7.62 0.300	300	1864060000 1863470000
4	11.43 0.450	300	1864290000 1863490000
5	15.24 0.600	300	1864300000 1863540000
6	19.05 0.750	300	1864310000 1863560000
7	22.86 0.900	300	1864320000 1863570000
8	26.67 1.050	300	1864330000 1863590000
9	30.48 1.200	300	1864340000 1863630000
10	34.29 1.350	300	1864350000 1863660000

Ordering data

Solder pin length		1.5 mm	3.2 mm
Colour		black	black
Pitch		3.81 mm	
Pol.	L1 (inch)	Qty.	Order No.
2	3.81 0.150	50	1864070000 1863230000
3	7.62 0.300	50	1864080000 1863250000
4	11.43 0.450	50	1864090000 1863260000
5	15.24 0.600	50	1864100000 1863280000
6	19.05 0.750	50	1864110000 1863300000
7	22.86 0.900	50	1864120000 1863310000
8	26.67 1.050	50	1864130000 1863340000
9	30.48 1.200	50	1864140000 1863360000
10	34.29 1.350	50	1864150000 1863380000
11	38.10 1.500	50	1864160000 1863390000
12	41.91 1.650	50	1864170000 1863410000
13	45.72 1.800	50	1864180000 1863430000
14	49.53 1.950	50	1864190000 1863440000
15	53.34 2.100	50	1864200000 1863460000
16	57.15 2.250	50	1864210000 1863480000

Ordering data

Solder pin length		1.5 mm	3.2 mm
Colour		black	black
Pitch		3.81 mm	
Pol.	L1 (inch)	Qty.	Order No.
2	3.81 0.150	300	1864220000 1863500000
3	7.62 0.300	300	1864230000 1863510000
4	11.43 0.450	300	1864240000 1863530000
5	15.24 0.600	300	1864250000 1863580000
6	19.05 0.750	300	1864260000 1863600000
7	22.86 0.900	300	1864270000 1863620000
8	26.67 1.050	300	1864280000 1863640000

Tape widths: 32, 44, 56, 72, 88

Tape widths: 32, 44, 56, 72, 88