


Specifications

Global Part Number	AS-V20NA-R
Previous Part Number	
Supply Voltage	2.5 to 3.5V
Current Consumption	5.0 to 12.0 μ A
Operating Magnetic Field (H->L)	4.0mT max.
Operating Magnetic Field (L->H)	0.8mT min.
High Level Output Voltage	
Low Level Output Voltage	
Operating Temp. Range	-40 to +85 $^{\circ}$ C
Storage Temp. Range	-40 to +125 $^{\circ}$ C

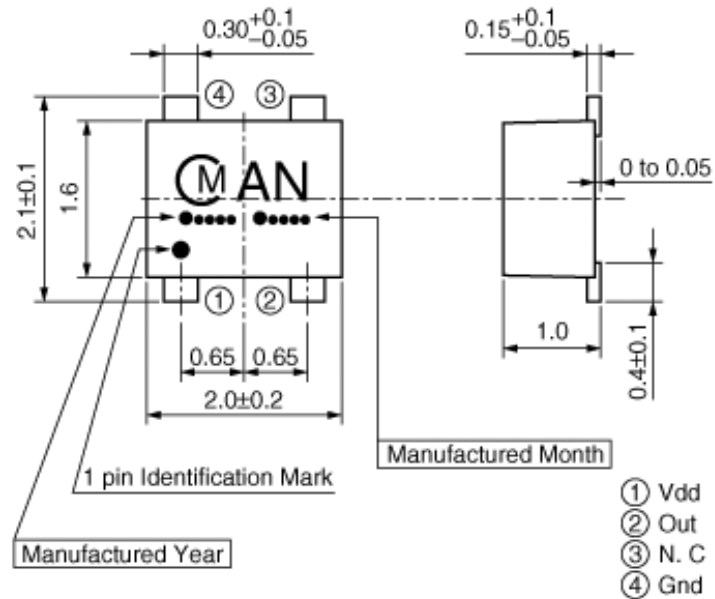

* Coplanarity: 0.1mm or less
(flatness applies to reflow process as well)

(in mm)