


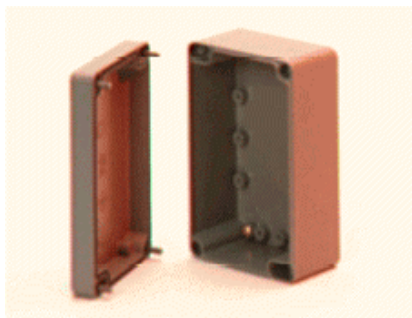

This is a sample photo.

**ORDER SYMBOL:** AL 082506

## EL.number

Sweden: 2536317  
Denmark: 8212004676  
Finland: 3423615

**EAN:** 6418074004147

**INCLUDING:**

Enclosure body, cover with PUR gasket, cover screws, 4 mounting screws and 2 earth screws.


**APPROVALS:**

USA: UL Type 1, 4, 4X, 12, 13 (E75645 Vol.1 Sec.6)

EURO: IP 67/IP 66

OTHERS: IEC 529

# FIBOX EURONORM II AL

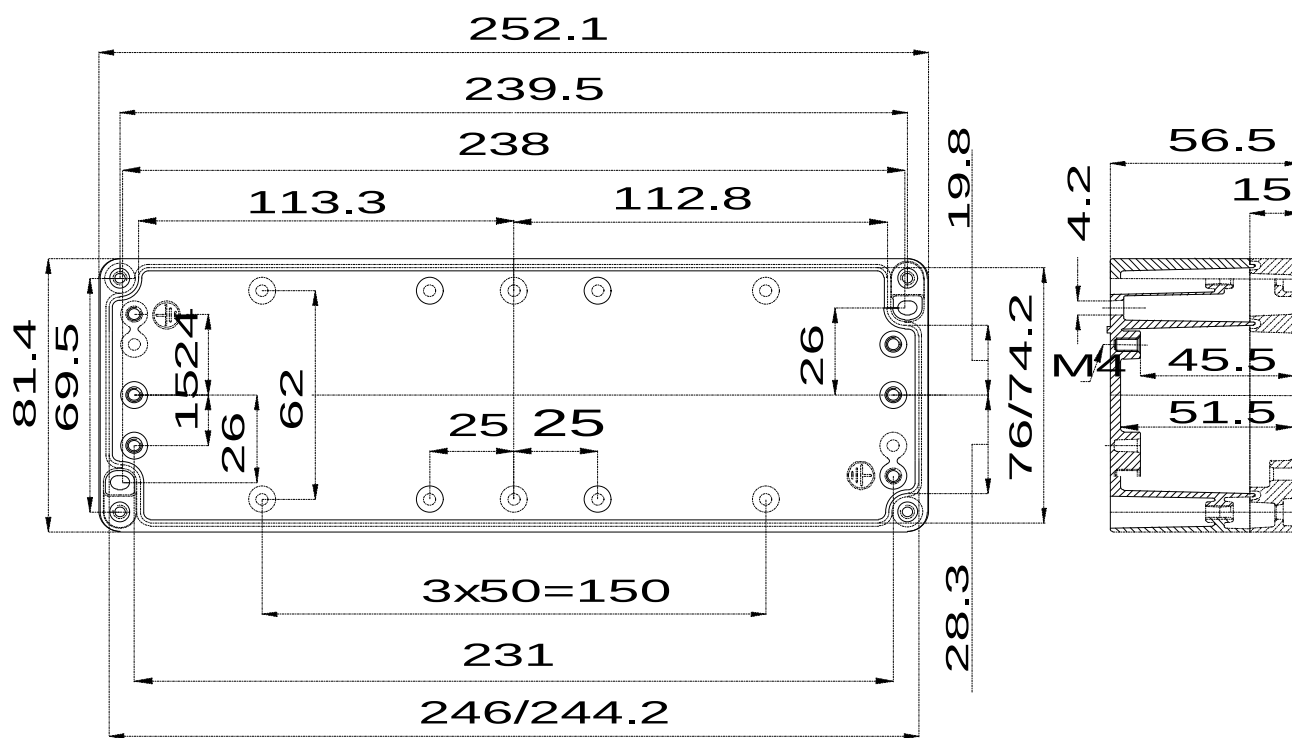

### TECHNICAL INFORMATION:

Standard colour: RAL 7001  
Ingress protection: IP 67 (IEC 529)  
Flame resistance:

Temp.range in cont. use: Max. +80 °C  
Temp. range of material: - 50 °C - + 120 °C

## ACCESSORIES

|          |          |          |          |               |           |
|----------|----------|----------|----------|---------------|-----------|
| DIN-Rail | ARH 12   | DIN-Rail | ARH 26   | DIN-Rail      | ARM 0818  |
| DIN-Rail | ARH 16   | DIN-Rail | ARH 36   | DIN-Rail      | ARM 0825  |
| DIN-Rail | ARH 1636 | DIN-Rail | ARH 40   | Fastening lug | MRS 28540 |
| DIN-Rail | ARH 1656 | DIN-Rail | ARH 60   | Fastening lug | MRS 28541 |
| DIN-Rail | ARH 22   | DIN-Rail | ARM 0610 |               |           |
| DIN-Rail | ARH 2320 | DIN-Rail | ARM 0615 |               |           |
| DIN-Rail | ARH 2328 | DIN-Rail | ARM 0808 |               |           |
| DIN-Rail | ARH 2333 | DIN-Rail | ARM 0813 |               |           |