



**fitted with**

- work equipment**
- connected load**
- power consumption**
- glare-free**
- system of protection**
- class of protection**
- technology**
- usage**
- luminaire body**
- material
- surface
- colour
- lamp cover**
- weight (net)**
- mains supply**

- fastening**
- dimension**
- special features**

- 4 x Light-emitting diode
- light colour neutral white, 5000 K, Color Rendering Index (CRI)=65
- without
- 24 V; DC
- approx. 24 W
- without
- IP 67
- III
- switchable
- without switch
- aluminium
- anodised
- aluminium coloured anodised
- screen, clear
- approx. 0.9 kg
- built-in plug
- RSFM 4/0.5M
- screws
- A=707mm, B=741mm, C=733mm
- angle of radiation 50°, integrated fastening clip




RSFM 4/0.5M

**illuminance**

measuring conditions: d=50cm

Em: 1077 lx  
 Emax: 2419 lx  
 Emin: 147 lx

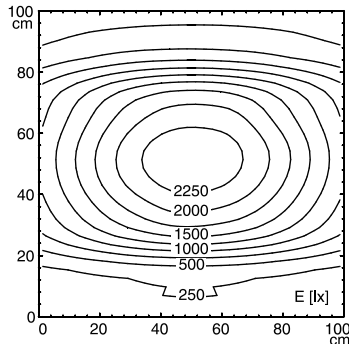

**luminous intensity**

