



### Features/applications:

- low energy consumption: 3 W → 15 W
- LED lamps for (retrofit) simple replacement of existing incandescent or halogen candle and luster lamps
- available in E14, E27 and B15 socket
- good colour rendering
- for indoor applications in open luminaires (open/free air gap of min. 10 mm)
- applications in hotels, restaurants, homes and historical buildings
- beautifully sparkling light for chandeliers, wall sconces and other decorative luminaires
- available in frosted (FR) and clear (CL) versions to suit any application

### Product benefits:

- 80% energy saving
- good colour rendering
- no IR and UV radiation, low heat radiation
- lower maintenance costs
- sparkling light, directed radially

### Features/applications:

- low energy consumption: 7 W → 50 W, 12 W → 75 W, 18 W → 100 W
- efficient replacement of halogen or incandescent PAR lamps
- very good colour rendering
- PAR20, PAR30 and PAR38 for indoor use in open luminaires (ventilated, min. 10 mm free air gap)
- PAR38 OD for outdoor use (please check the packaging guidelines for outdoor installation requirements)
- especially suitable for public areas like lobbies, corridors and stairwells

### Product benefits

- long lifetime
- 80% energy saving
- good colour rendering
- no IR and UV radiation
- lower maintenance costs



### Technical specification


Product description Novallure	Wattage	Comparable incandescent Wattage	Socket	Bulb shape	Lifetime	Dimmable*	Lumen output	Efficacy	Units per pack	Colour rendering index	Colour temp.	EOC 8727900	EOC 8719291
	(W)	(W)			(hours)		(lm)	lm/W			K		
D 3W E14 2700K 230V B35 CL	3	15	E14	B35	20,000	yes	136	45	10	>80	2700	93456400	
D 3W E14 2700K 230V B35 FR	3	15	E14	B35	20,000	yes	136	45	10	>80	2700	93458800	
D 3W E14 2700K 230V P45 CL	3	15	E14	P45	20,000	yes	136	45	10	>80	2700	93468700	
D 3W E14 2700K 230V P45 FR	3	15	E14	P45	20,000	yes	136	45	10	>80	2700	93470000	
D 3W E27 2700K 230V P45 CL	3	15	E27	P45	20,000	yes	136	45	10	>80	2700	93472400	
D 3W E27 2700K 230V P45 FR	3	15	E27	P45	20,000	yes	136	45	10	>80	2700	93474800	
D 3W B15 2700K 230V B35 CL	3	15	B15	B35	20,000	yes	136	45	10	>80	2700		12731400

\* Please refer to the site [www.philips.com/masterled](http://www.philips.com/masterled) for the latest information about dimming MASTER LED lamps.

### Technical specification

Product description MASTER LEDspot	Wattage	Comparable Wattage	Socket	Bulb shape	Beam intensity	Beam angle	Lifetime	Dimmable*	Lumen output	Efficacy	Units per pack	Colour rendering index	Colour temp.	EOC 8727900	EOC 8718291
	(W)	(W)			(cd)	(°)	(hours)		(lm)	lm/W			K		
D 7-50W 2700K PAR20 25D	7	50	E27	PAR20	1000	25	45,000	yes	250	36	6	>80	2700	93398700	
D 7-50W 2700K PAR20 40D	7	50	E27	PAR20	450	40	45,000	yes	250	36	6	>80	2700	93406900	
D 7-50W 3000K PAR20 25D	7	50	E27	PAR20	1050	25	45,000	yes	260	37	6	>80	3000	93400700	
D 7-50W 3000K PAR20 40D	7	50	E27	PAR20	500	40	45,000	yes	260	37	6	>80	3000	93408300	
D 7-50W 4000K PAR20 25D	7	50	E27	PAR20	1200	25	45,000	yes	280	40	6	>80	4000	93402100	
D 7-50W 4000K PAR20 40D	7	50	E27	PAR20	550	40	45,000	yes	280	40	6	>80	4000	93410600	
12W 2700K 230V PAR30S 25D	12	75	E27	PAR30S	2250	25	45,000	yes	630	53	6	>80	2700		11927200
<b>new</b> 17W 2700K 230V PAR38 OD	17	100	E27	PAR38	3500	25	25,000	no	810	48	10	>80	2700		11931900
18W 2700K 230V PAR38 25D	18	100	E27	PAR38	3400	25	45,000	yes	810	45	6	>80	2700		11929600

\* Please refer to the site [www.philips.com/masterled](http://www.philips.com/masterled) for the latest information about dimming MASTER LED lamps.

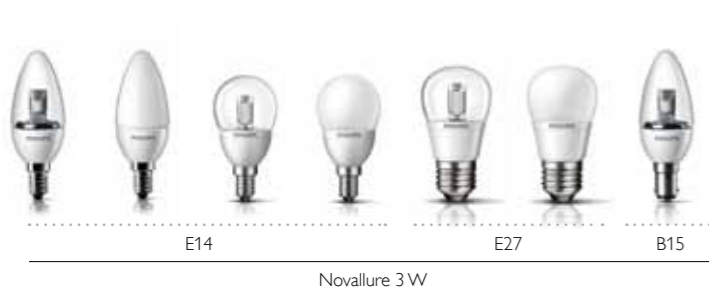

Dimensions (mm) / weight (kg)			
Product	C	D	Weight
candle 3-15W	101	35	0.034
luster 3-15W E14	83.5	45	0.032
luster 3-15W E27	92	46	0.032
candle 3-15W B15	98	35	0.041

Dimensions (mm) / weight (kg)			
Product	C	D	Weight
PAR20	90.2	63.7	0.156
PAR30S	91	92	0.290
PAR38	133	121.5	0.525
PAR38 OD	132.5	121.6	0.530