

SES-MARKERS® code marker cards

Self adhesive, self protected EV strips
white marking area



SES-MARKERS®
Quality EV



EV

Material: PVC transparent
Temperature range: -20 to +70°C
Operating temperature: +5 to +40°C
Adhesive: rubber
Adhesion on steel: > 3 N/cm
Tensile strength: 25 N/cm


Dimension of the card: 255 x 82 mm

Strip thickness: 0,15 mm
Standard colour: white




Pack: 10 cards

Specification:

- Marking by hand (with Nylon-point pen, biro or pencil).
- Self protection by foil strip.
- Resistant to oils and light solvents.
- Possibility of LASER marking for a readable and indelible marking (please contact us).

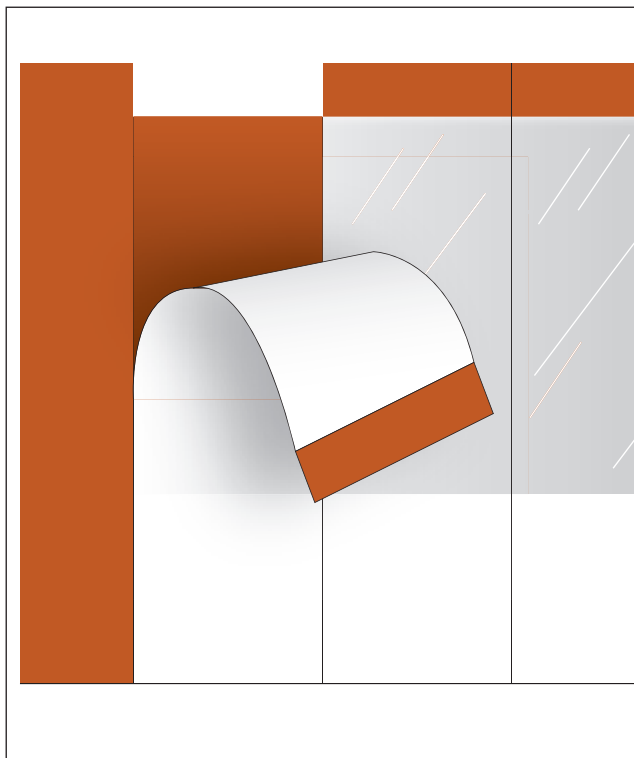

type	art. no.	dimensions of the strip A x C (mm)	for cable Ø (mm)	printing surface A x B (mm)	quantity of strips/card	
EV 75/9	0307 0001 001	25 x 75	8 - 16	25 x 22	9	10
EV 112/6	0307 0002 001	25 x 112,5	8 - 28	25 x 22	6	10
EV 112/4	0307 0003 001	37,5 x 112,5	8 - 28	37,5 x 22	4	10
EV 225/2	0307 0004 001	37,5 x 225	8 - 64	37,5 x 22	2	10

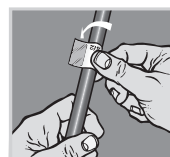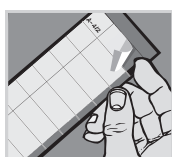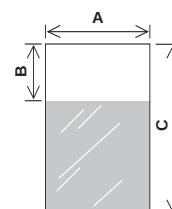

Other colours upon request.

Permanent marker pen QUICK-MARKERS®

type	art. no.	colour	point	
EV-permanent	0307 0501 010	black	medium	1
PLIO-404 permanent	0307 0502 010	black	fine	1
PLIO-404 permanent	0307 0503 007	red	fine	1
PLIO-780 opaque	0307 0504 001	white	fine	1



SES-MARKERS® code marker cards
Self adhesive, self protected EV 10 strips
printed



SES-MARKERS®
Quality EV




EV 10

Material: PVC transparent
Temperature range: -20 to +70°C
Operating temperature: +5 to +40°C
Adhesive: rubber
Adhesion on steel: > 3 N/cm
Tensile strength: 25 N/cm

Dimension of the card: 255 x 64 mm
Print height: 2,3 mm

Strips per card: 100 strips
Strip width: 4,5 mm
Strip length: 25 mm (for cables up to Ø 5,5 mm)
Strip thickness: 0,15 mm
Standard colour: white

Pack: 10 cards same legend (for smaller quantities, an extra charge will be applied).

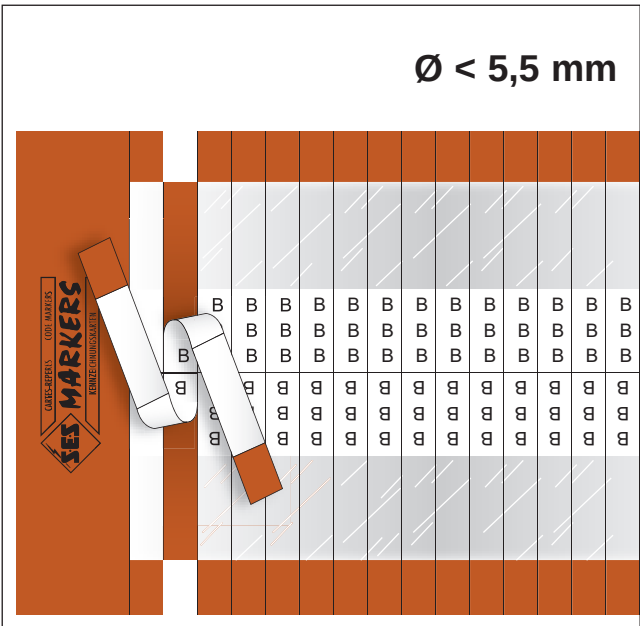

Article number

code group	detail article	code colour	code legend
0307	0010	001	x x x x

Example for order:
Strip EV 10 white - legend M

0307	0010	001	M
------	------	-----	---

legend	code legend	number strips /card	legend	code legend	number strips /card	legend	code legend	number strips /card
0	0	100	A	A	100		SYTE	100
1	1	100	B	B	100			
2	2	100	C	C	100			
3	3	100	D	D	100			
4	4	100	E	E	100			
5	5	100	F	F	100			
6	6	100	G	G	100			
7	7	100	H	H	100			
8	8	100	I	I	100			
9	9	100	J	J	100			
10	10	100	K	K	100			
11	11	100	L	L	100			
12	12	100	M	M	100			
13	13	100	N	N	100			
14	14	100	O	O	100			
15	15	100	P	P	100			
16	16	100	Q	Q	100			
17	17	100	R	R	100			
18	18	100	S	S	100			
19	19	100	T	T	100			
20	20	100	U	U	100			
			V	V	100			
			W	W	100			
			X	X	100			
			Y	Y	100			
			Z	Z	100			

Other legends upon request. Minimum quantity for order 10 cards.



SES-MARKERS® code marker cards

Self adhesive, self protected EV 20 strips
printed



SES-MARKERS®
Quality EV



EV 20


Material: PVC transparent
Temperature range: -20 to +70°C
Operating temperature: +5 to +40°C
Adhesive: rubber
Adhesion on steel: > 3 N/cm
Tensile strength: 25 N/cm

Dimension of the card: 255 x 64 mm
Print height: 3,2 mm

Strips per card: 37 strips
Strip width: 6 mm
Strip length: 50 mm (for cables up to Ø 10 mm)
Strip thickness: 0,15 mm
Standard colour: white

Pack: 10 cards same legend (for smaller quantities, an extra charge will be applied).

Ø < 10 mm

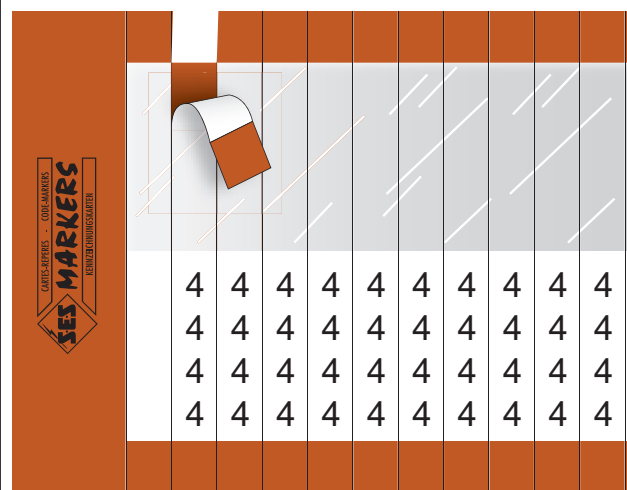

Article number

code group	detail article	code colour	code legend
0307	0020	001	x x x x

Example for order:

Strip EV 20 white - legend M

0307	0020	001	M						
------	------	-----	---	--	--	--	--	--	--

legend	code legend	number strips /card	legend	code legend	number strips /card
0	0	37	A	A	37
1	1	37	B	B	37
2	2	37	C	C	37
3	3	37	D	D	37
4	4	37	E	E	37
5	5	37	F	F	37
6	6	37	G	G	37
7	7	37	H	H	37
8	8	37	I	I	37
9	9	37	J	J	37
10	10	37	K	K	37
11	11	37	L	L	37
12	12	37	M	M	37
13	13	37	N	N	37
14	14	37	O	O	37
15	15	37	P	P	37
16	16	37	Q	Q	37
17	17	37	R	R	37
18	18	37	S	S	37
19	19	37	T	T	37
20	20	37	U	U	37
			V	V	37
			W	W	37
			X	X	37
			Y	Y	37
			Z	Z	37

Other legends upon request. Minimum quantity for order 10 cards.