


**SKBI 64/F48**

Order No.: 2264093



Plug-in card block, Nominal current: 4 A, Number of positions: 64,  
Pitch: 0 mm, Connection method: Screw connection, Color: green

**Commercial data**

EAN	 4 017918 053918
Pack	1
Customs tariff	85369010
Country of Origin	DE
Catalog page information	Page 553 (CC-2011)

**Product notes**

WEEE/RoHS-compliant since:  
02/06/2006



Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation at <http://www.download.phoenixcontact.com>. The General Terms and Conditions of Use apply to Internet downloads.

**Technical data****Dimensions / positions**

Length	66 mm
Height	162 mm
Width	118 mm
Pitch	0 mm
Number of positions	64

Hole diameter	4.2 mm
Screw thread	M3
Tightening torque, min	0.5 Nm
Tightening torque max	0.6 Nm

#### Technical data

Range of articles	SKBI 64
Connection in acc. with standard	EN-VDE
Nominal current $I_N$	4 A
Nominal voltage $U_N$	250 V (in acc. with DIN VDE 0110/Gr.B)
Nominal cross section	2.5 mm <sup>2</sup>
Stripping length	8 mm

#### Connection data

Conductor cross section solid min.	0.2 mm <sup>2</sup>
Conductor cross section solid max.	4 mm <sup>2</sup>
Conductor cross section stranded min.	0.2 mm <sup>2</sup>
Conductor cross section stranded max.	2.5 mm <sup>2</sup>
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12

#### Certificates



Certification

GOST

#### Accessories

Item	Designation	Description
------	-------------	-------------


#### Assembly

2263007	SF-SKBI 64	Snap foot, for horizontal or vertical mounting of the SKBI plug-in card blocks, on the NS 35/7.5 DIN rail
---------	------------	---

---

## Drawings

### Dimensioned drawing

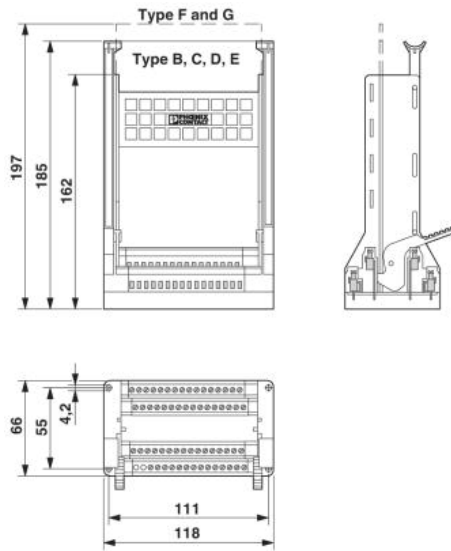

### Schematic diagram

