

## Classic ECO A55

CLECO A55 240V 42W E27 SV1

0023767

### Range features



### PRODUCT OVERVIEW

Ordering number	0023767
Light colour	828 Homelight
Technology	Halogen
Energy class	D
Average life (Rated) (h)	2000
Lamp finish	Clear
Lamp shape	GLS A55
Dimmable	Yes
Cap/Base	E27
Type	Classic 'A' Shape
EAN code	5410288237671
CRI (Ra)	100
Beam angle(°)	na
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	625
Watt (Nominal) (W)	42
Equivalent watt (W)	55
Voltage (V)	240

## Classic ECO A55

CLECO A55 240V 42W E27 SV1

0023767

### DATA TABLE

#### General data

Ordering number	0023767
Technology	Halogen
Average life (Rated) (h)	2000
Average life (Nominal) (h)	2000
Energy class	D
Energy saving lamp	No
Lamp shape	GLS A55
Lamp finish	Clear
Dimmable	Yes
Cap/Base	E27
Type	Classic 'A' Shape
EAN code	5410288237671
E-number FI	4740161
E-number SE	8355962
Product name	CLECO A55 240V 42W E27 SV1
Lamp mercury content (mg)	0
Starting time (max) (s)	0.01
Warm-up time to 60% of full light (max) (s)	Instant full light
Control gear required	No
Fixture rating	Open
IEC Reference	IEC 60357
IEC Reference 2	IEC 60432-2
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	> 8000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25

#### Optical data

Light colour	828 Homelight
CRI (Ra)	100
Suitable for accent lighting	No
Beam angle(°)	na
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	625
Lumen maintenance at end of nominal life (%)	80
Luminous flux (Nominal) (lm)	625

# Classic ECO A55

CLECO A55 240V 42W E27 SV1

**0023767**

## Electrical data

<b>kWh per 1000 hours burning time</b>	42
<b>Watt (Rated) (W)</b>	42
<b>Watt (Nominal) (W)</b>	42
<b>Equivalent watt (W)</b>	55
<b>Voltage (V)</b>	240
<b>Lamp power factor</b>	1

## Physical data

<b>Weight (kg)</b>	0.03
<b>Lamp Length (mm) - C/L</b>	100
<b>Max. Lamp Diameter (mm) - D</b>	56
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	9.60 x 5.50 x 5.50
<b>Inner package dimensions (L x W x H) (cm)</b>	28.00 x 11.00 x 10.00
<b>Inner package net weight (kg)</b>	0.28
<b>Outer package dimensions (L x W x H) (cm)</b>	59.00 x 30.50 x 22.50


## Classic ECO A55

CLECO A55 240V 42W E27 SV1


0023767

### TECHNICAL DRAWINGS

Classic ECO A55

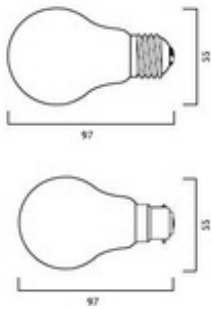

E27

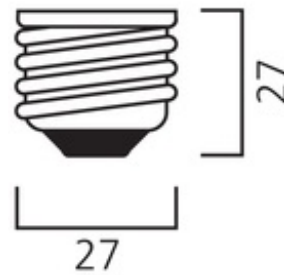

### ENERGY LABEL

