
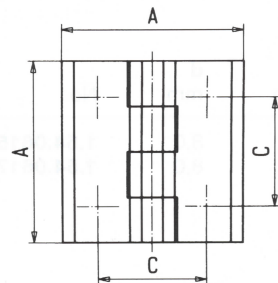


Hinge
Polycarbonate black
Pin stainless steel

A mm	C mm	H mm	S mm	d mm	D mm	D1 mm	T mm	No.
40	25	9	5	4	10,5	5,3	2,5	0.54.0504.0
50	30	11,5	6	6	12,5	6,4	3	0.54.0505.0
60	36	15	8	8	16,5	8,5	3,7	0.54.0506.0

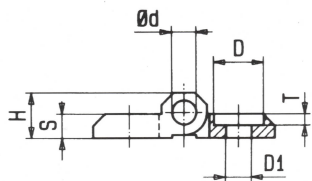

Hinge
Polycarbonate black
Pin stainless steel

A mm	C mm	H mm	S mm	d mm	M mm	L mm	No.
40	25	9	5	4	M5	12	0.54.0514.0
50	30	11,5	6	6	M6	12	0.54.0515.0
60	36	15	8	8	M8	14	0.54.0516.0

