

Digital Indicator MarCator1075 R

Features

Function:

ON/OFF, RESET (set display to zero), mm/inch, Reversal of counting direction, PRESET (for entering a numerical value), DATA (Data transmission via connection cable), LOCK function (key lock), AUTO-ON / OFF

Product features:

- High contrast LCD
- Hermetically sealed protective measuring spindle cap
- Mounting shank and measuring spindle are both made of hardened stainless steel

Energy supply:

Battery, life span ca. 3 years

Scope of delivery:

- Battery
- Instruction manual




Order-No.: **4336010**

Technical Data

Measuring span	12,5 mm
Measuring range in inch	0,5 in
Resolution	0,01 mm
Resolution inches	.0005"
Error limit	0,02 mm
Measuring force	0.5 - 1
Height of digits	12 mm

Dimensions

Mounting shaft	8 mm
----------------	------

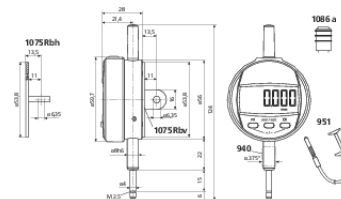

Accessories

Bezeichnung	Typ	Artikel-Nr.
Data Connection Cable USB	16 EXu	4102357
Digimatic data cable	16 EWd	4102915
Data Connection Cable RS232C	16 EXr	4102410
Adapter bush	940	4310103
Cable release	951	4372000
Lug back, horizontal	1075 Rbh	4336041
Lug back, vertical	1075 Rbv	4336042