


Capacitor, film, 0.56 uF, +/-10% Tol, -55/+105C, General Purpose, 250V@85C, Lead Spacing=15 mm

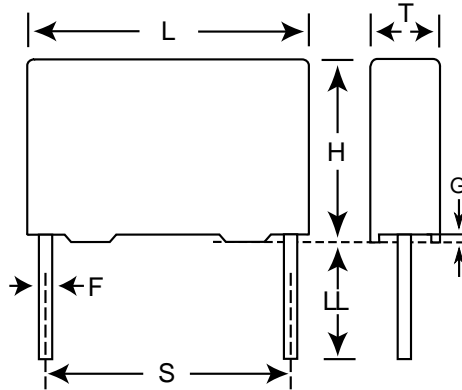

Dimensions (mm)		
Symbol	Dimension	Tolerance
L	18	Max
H	12	Max
T	6	Max
S	15	+/-0.4
LL	18.5	+/-0.5
G	0.5	Nom
F	0.8	+/-0.05

Notes:  
 -BG

General Information	
Manufacturer:	KEMET
Miscellaneous Electrical:	The rated voltage decreases 1.25%/C between +85C and +105C (For +125C, please consult KEMET)

Specifications	
Capacitance:	0.56 uF
Rated Temperature:	85C
Voltage @ rated temp:	250V
Voltage AC:	160VAC
Tolerance:	+/-10%
Body Type:	Radial Box
Dielectric:	Metallized Polyester
Application:	General Purpose
Temperature Range:	-55/+105C
Dissipation Factor @ 1 kHz:	0.8%
Dissipation Factor @ 10 kHz:	1.5%
Insulation Resistance:	17.86 GOhm
Inductance:	6 nH
Maximum dVdT:	12v/us

Packaging Specifications	
Package Kind:	T&R
Package Size:	355mm
Package Quantity:	500