

Datasheet

RS Pro P13.5s Filament Indicator Lamp, Clear, 4 V, 500 mA, 15h

RS Stock No: **105-168**



Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton and Xenon gas for super-high brightness. It has a voltage rating of 4 V and current rating of 500 mA. The lamp has 15 h life.

Features and Benefits

- Alternative to vacuum types
- P13.5s prefocus base
- Clear lens




Specifications:

Current Rating	500 mA
Diameter	9.3 mm
Lamp Base	P13.5s
Lamp Size	T9
Length	31 mm
Lens Colour	Clear
Life Hours	15 h
Luminosity	33 lm
Voltage Rating	4 V

RS Stock No.

105168

DRAWING - I

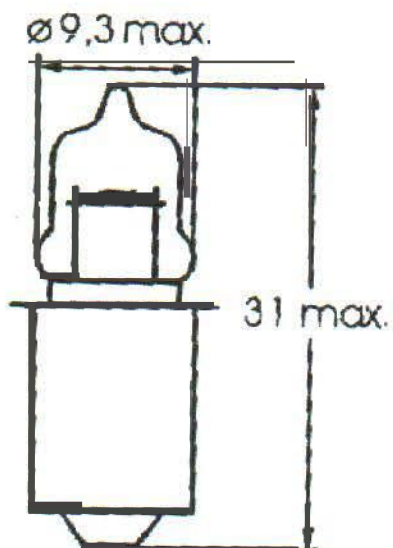

Unit : mm

1. Structure	Bulb Type	T9x28
	Bulb Diameter	Ø9.3Max.
	Length	31.0Max
	Base Type	P13.5s
2. Design Characteristics	Voltage	4V
	Amperage	500mA± 10%
	Gas Type	Halogen gas-filled
	Luminous Flux	33Lm±20%
	Life Hours	15Hrs