

Standard RPTS S255

24 Hour, 4-pin Time Switch with 2 or 3 ON/OFF Operations without Battery Reserve





Benefits

S255 - 24 hour quartz controlled without battery reserve, 4 pin base.

- .2 - Up to two ON and two OFF operations per day.
.3 - Up to three On and three OFF operations per day.

The 24 hour programming cycle performs the same sequence of switching operations on each day and can be quickly and easily set using the small manual levers on the dial. A “day omit” device allows you to select any number of days in the week on which the switching cycle can be disabled. A general purpose timeswitch for heating, ventilation and equipment control applications.

Dimensions

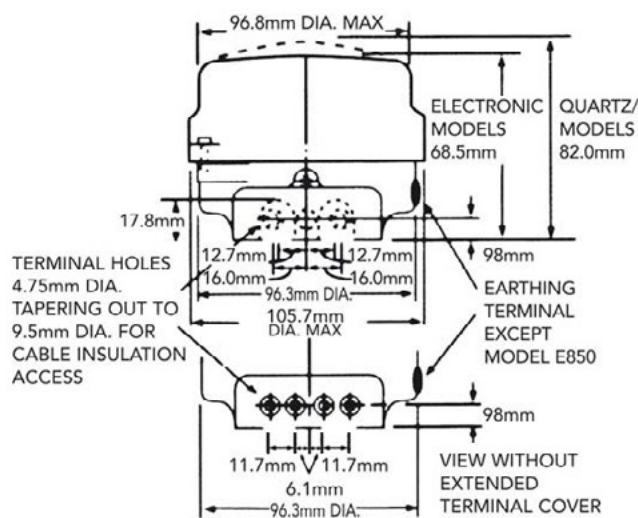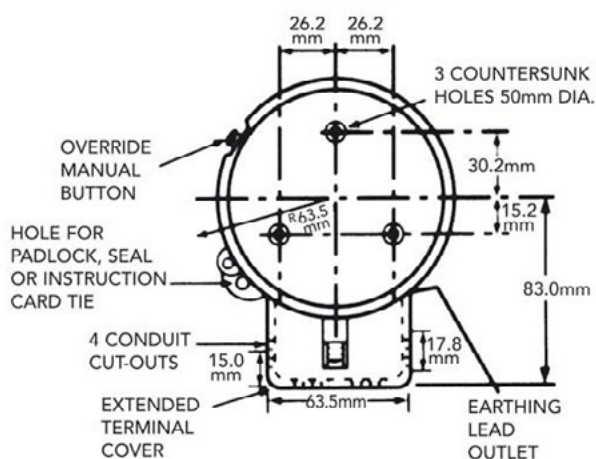


Technical Data

Programming	24 hour programme with 2 or 3 ON/OFF operations per day
Display	24 hour dial
Mounting	Surface mounting
Current Rating	SPST: 20amp resistive
Supply	230V, 50/60 Hz a.c.
Base Type	4 Pin
Reserve	none
Day Omission	Yes (omits the "ON" operation)
Temp Override Facility (Manual Button)	Advance to "OFF", when program "ON" and will remain "OFF" unit next "ON" operation and vice versa
Cable Size	6.0mm ²
Timing Accuracy	5 mins/year
Power Consumption	0.6W at 230V
Ambient Temperature Range	Designed to operate over a temperature range of 0oC to 50oC continuous
Live Parts Protection	This timer is totally protected by its enclosure
Dirt Protection	Normal domestic dust deposits only
Moisture Protection	Ordinary: has no special protection against moisture
Shock Protection	Class 1 (Product must be earthed)
Dial Calibration	15 min divisions
Setting Accuracy	+/- 3 minutes
Period Between unlike Operations	15 minutes minimum
Period Between like Operations	1¾ hours minimum
BEAB Approval	Yes
Dimensions	Height (wall mounted) 136mm, width 105.7mm, projection 82mm, (Total height 146.5mm)

Electrical Connections

Internal Wiring Diagram

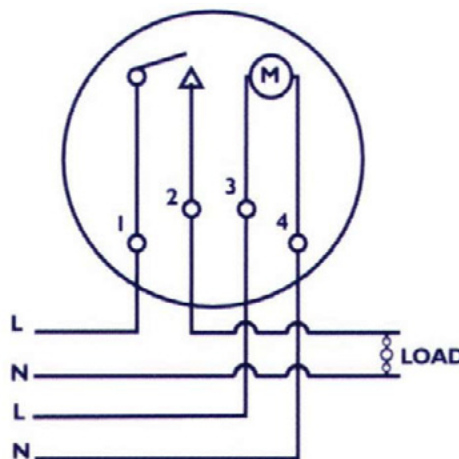

Technical Helpline: 01475 745131

CUSTOMER CARE POLICY

As part of Sangamo's continuous improvement program, the Company operates a Customer Care Policy. This means that we welcome your comments and complaints, as it can only help us to improve our services to you, our customer.

SANGAMO



Certificate Q05237



Certificate EMS 80426

Sangamo Limited, Industrial Estate, Port Glasgow,
Renfrewshire PA14 5XG

Tel: 01475 745131 Fax: 01475 744567

Email : enquiries@sangamo.co.uk Web: www.sangamo.co.uk

RPTS002B