



ex 317 C

Tube cutter for plastic tubes and profiles

- Ratchet-type model for an effortless progressive cutting action
- Suitable for quick cut of PVC, PP, PE, PER, ABS, PEHD tubes
- Blade treated for square cuts without burrs
- Light alloy body
- Enamelled finish

Ø mm	Ø"	kg	code	
63	2,1-2 1/2	1,2	V211463	1



ex 317 CA

Spare blade

kg	code	
200	V211403	1




ex 317 K

Tube cutter for plastic tubes

- For cutting tubes in PVC-PP-PE
- Shock resistant plastic body

Ø mm	Ø"	kg	code	
28	1	170	V214026	1

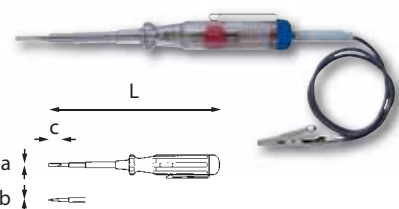

322 C1

UNI 7076 ISO 2380 DIN 5264

Circuit-testing screwdriver 6÷24 Volts

- Model with grip and sheath thermoformed in one piece
- Silicon Chrome Vanadium steel blade


axbxc mm	L mm	code	
0,6x3,5x20	160	322303	5



322 C1R

Spare bulb

kg	code	
1	Q322305	10

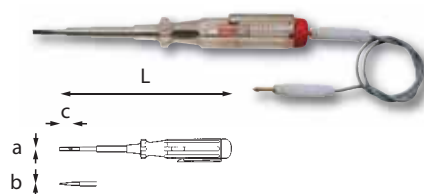


322 C2

UNI 10562 ISO 2380 DIN 5264

Circuit-testing screwdriver 110÷380 Volts

- Model with grip and sheath thermoformed in one piece
- Silicon Chrome Vanadium steel blade

axbxc mm	L mm	code	
0,6x3,5x20	160	322301	5

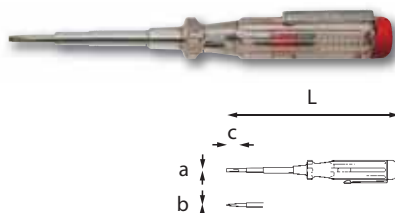

322 F

UNI 10562 ISO 2380 DIN 5264

Phase-testing screwdriver 110÷380 Volts

- Model with grip and sheath thermoformed in one piece
- Silicon Chrome Vanadium steel blade

axbxc mm	L mm	code	
0,6x3,5x20	160	322401	5




322 C2R

Spare bulb

- For 322 C2 and 322 F

kg	code	
1	322402	10

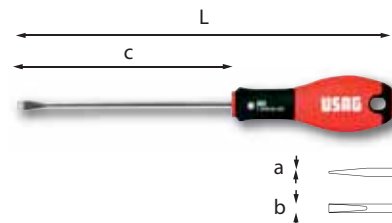


322

UNI 10562 ISO 2380 DIN 5264

Screwdrivers for slot-head screws

- Ergonomic bimaterial grip
- Chrome Vanadium steel blade
- Chrome plated finish with sandblasted tip

axbxc mm	L mm	code	
0,4x2,5x75	148	03220005	5
0,5x3x75	173	03220006	5
0,5x3x100	198	03220007	5
0,8x4x100	202	03220008	5
0,8x4x125	227	03220009	5
1x5,5x100	205	03220011	5
1x5,5x125	230	03220012	5
1,2x6,5x125	241	03220014	5
1,2x6,5x150	266	03220015	5
1,6x8x175	291	03220017	5
1,6x10x200	275	03220023	5
2x12x250	366	03220024	5
0,4x2x50	148	03220025	5
0,6x3,5x100	173	03220028	5

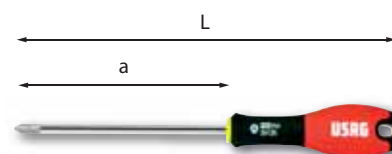


322 PH

UNI ISO 8764 DIN 5260

Screwdrivers for PHILLIPS® screws

- Ergonomic bimaterial grip
- Chrome Vanadium steel blade
- Chrome plated finish with sandblasted tip

n°xa	L mm	code	
0x75	177	03220039	5
1x100	205	03220041	5
2x125	230	03220043	5
3x150	266	03220047	5

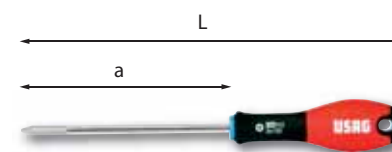


322 PZ

UNI ISO 8764 DIN 5260

Screwdrivers for POZIDRIV®-SUPADRIV® screws

- Ergonomic bimaterial grip
- Chrome Vanadium steel blade
- Chrome plated finish with sandblasted tip

n°xa	L mm	code	
0x75	177	03220056	5
1x100	205	03220057	5
2x125	230	03220058	5

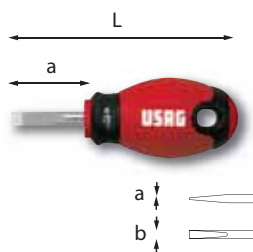


322 N UNI 10562 ISO 2380 DIN 5264

Screwdrivers for slot-head screws

- Stubby model
- Ergonomic bimaterial grip
- Chrome Vanadium steel blade
- Chrome plated finish with sandblasted tip

axbxc mm	L mm	code	
0,8x4x30	90	03220063	5
1x5,5x30	90	03220064	5
1,2x6,5x30	90	03220065	5

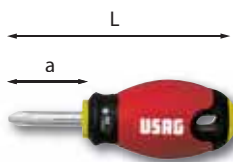

322 NPH UNI 10562 ISO 2380 DIN 5264

Screwdrivers for Phillips® screws

- Stubby model
- Ergonomic bimaterial grip
- Chrome Vanadium steel blade
- Chrome plated finish with sandblasted tip

n°xa	L mm	code	
1x30	90	03220068	5
2x30	90	03220069	5



322 SH5

Set of five screwdrivers for slot-head and PHILLIPS® screws

- 322 0,6x3,5x75-0,8x4x100-1x5,5x100
- 322 PH/1x100-2x125

gr	code	
450	03220253	1



322 SH7

Set of seven screwdrivers for slot-head and PHILLIPS® screws

- 322 0,4x2x50-0,5x3x75-0,8x4x100-1x5,5x100-1,2x6,5x150
- 322 PH/1x100-2x125

gr	code	
600	03220254	1




322 SH10

Set of ten screwdrivers for slot-head, PHILLIPS® and POZIDRIV® screws

- 322 0,4x2x50-0,5x3x75-0,8x4x100-1x5,5x100-1,2x6,5x150
- 322 PH/0x75-1x100-2x125
- 322 PZ 1x100-2x125

gr	code	
800	03220255	1

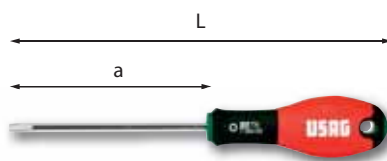

322 TX

Screwdrivers for TORX® screws

- Ergonomic bimaterial grip
- Molybdenum Vanadium steel blade
- Chrome plated finish with sandblasted tip

n°xa	L mm	code	
T6x50	148	03220071	5
T7x50	148	03220072	5
T8x50	148	03220073	5
T9x75	173	03220074	5
T10x75	177	03220075	5
T15x75	177	03220076	5
T20x100	202	03220077	5
T25x100	205	03220078	5
T27x100	205	03220079	1
T30x125	241	03220080	1
T40x125	241	03220081	1




322 TX/S11

Set of eleven screwdrivers for TORX® screws

- 322 TX T6x50-T7x50-T8x50-T9x50-T10x75-T15x75-T20x100-T25x100-T27x100-T30x125-T40x150

gr	code	
900	03220266	1

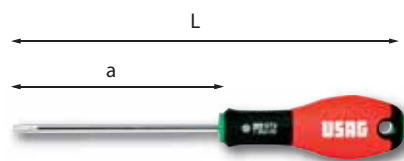

322 STX

Screwdrivers for TORX® Tamper Resistant® screws

- Ergonomic bimaterial grip
- Molybdenum Vanadium steel blade
- Chrome plated finish with sandblasted tip

n°xa	L mm	code	
T10x75	175	03220086	5
T15x75	185	03220087	5
T20x100	210	03220088	5
T25x100	210	03220089	5
T27x100	230	03220090	1
T30x125	230	03220091	1
T40x125	250	03220092	1



322 STX/S7

Set of seven screwdrivers for TORX® Tamper Resistant® screws

- 322 STX T10x75-T15x75-T20x100-T25x100-T27x100-T30x125-T40x150

gr	code	
600	03220263	1