

Classic ECO A55

CLECO A55 240V 18W B22 SV1

0023131

Range features



PRODUCT OVERVIEW

Ordering number	0023131
Light colour	828 Homelight
Technology	Halogen
Energy class	D
Average life (Rated) (h)	2000
Lamp finish	Clear
Lamp shape	GLS A55
Dimmable	Yes
Cap/Base	B22
Type	Classic 'A' Shape
EAN code	5410288231310
CRI (Ra)	100
Beam angle(°)	na
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	180
Watt (Nominal) (W)	18
Equivalent watt (W)	21
Voltage (V)	240

Classic ECO A55

CLECO A55 240V 18W B22 SV1

0023131

DATA TABLE

General data

Technology	Halogen
Ordering number	0023131
Average life (Nominal) (h)	2000
Average life (Rated) (h)	2000
Energy saving lamp	No
Energy class	D
Lamp finish	Clear
Lamp shape	GLS A55
Dimmable	Yes
Cap/Base	B22
Type	Classic 'A' Shape
EAN code	5410288231310
E-number SE	8355982
Product name	CLECO A55 240V 18W B22 SV1
Lamp mercury content (mg)	0
Starting time (max) (s)	0.01
Warm-up time to 60% of full light (max) (s)	Instant full light
Control gear required	No
Fixture rating	Open
IEC Reference	IEC 60357
IEC Reference 2	IEC 60432-2
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	> 8000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25

Optical data

Light colour	828 Homelight
CRI (Ra)	100
Suitable for accent lighting	No
Beam angle(°)	na
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	180
Lumen maintenance at end of nominal life (%)	80
Luminous flux (Nominal) (lm)	180

Classic ECO A55

CLECO A55 240V 18W B22 SV1

0023131

Electrical data

kWh per 1000 hours burning time	18
Watt (Rated) (W)	18
Watt (Nominal) (W)	18
Equivalent watt (W)	21
Voltage (V)	240
Lamp power factor	1

Physical data


Weight (kg)	0.03
Lamp Length (mm) - C/L	98.5
Max. Lamp Diameter (mm) - D	56
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	9.60 x 5.50 x 5.50
Inner package dimensions (L x W x H) (cm)	28.00 x 11.00 x 10.00
Inner package net weight (kg)	0.28
Outer package dimensions (L x W x H) (cm)	59.00 x 30.50 x 22.50

Classic ECO A55

CLECO A55 240V 18W B22 SV1

0023131

TECHNICAL DRAWINGS

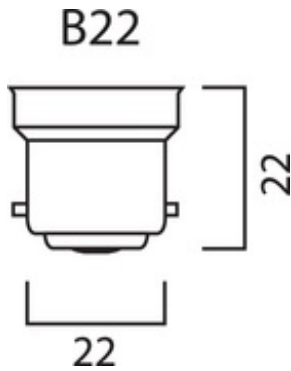

ENERGY LABEL

