

4 core coiled unshielded keyboard lead



Part NO: RGW-1563

Product Code: 4 core coiled unshielded keyboard lead

Product Description

Application:

For communication and signal control systems.

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

4

Cable Construction

Conductor	Bare Copper
Construction	0.12±0.005x22
Stranded Dia.(±0.01mm)	0.65
Insulation	PVC
Thickness	0.36
Insulation Dia.(±0.1mm)	1.40
Insulation Color	Red; White;Brown; Blue
Filler	Chalk
Jacket	PVC
Thickness(mm)	1.00
Dia.(±0.2mm)	5.70
Jacket Color	Black

Marking


No Printing

PACKAGING


1.65M/plastic Bag

100 Pcs/Box

Coil size

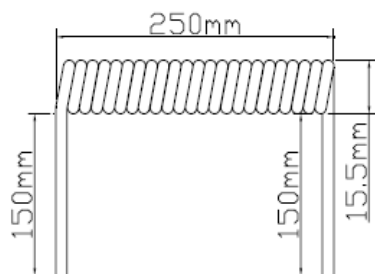


Boxes size:50x28x32cm

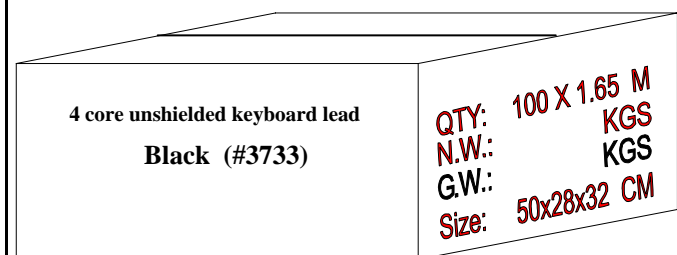

Revision History

A0-1

Design

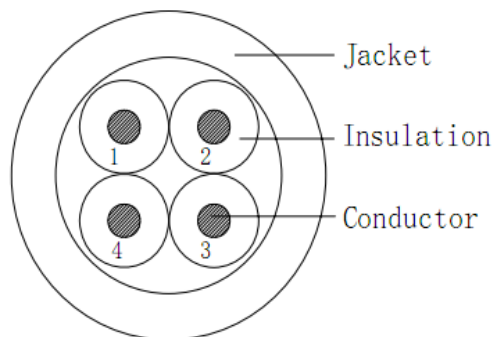

Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω/Km)	74.8
Min.Insulation DC Resistance at 20°C (MΩ *Km)	>500
Rated Temperature(°C)	-20 to +80
Rated Voltage(V)	100

Label on Plastic bag

Product label

4 core unshielded keyboard lead
Black
1.65M
RoHS(2002/95/EC) Compliant
WW/YY

RS label

7492493
 1.65M
 Made in China

Date: 2011-09-13

Page: 1 / 1