



TECHNICAL DATASHEET

SpotClip-Box

DESCRIPTION

Like all the SpotClip range, the goal of this product is to avoid any contact between the insulation and the bulb, but also to make the assembly airtight to prevent any calories exchange between inside room and outdoor.

SpotClip is supplied in a complete kit:

1 Round Base with 80mm hole for spot; **1 Basket** that fits on the top of this round base thanks to a bayonet system. This basket includes an area to hold the connection from the power supply; **1 Cover** to close this connection area; **1 Rubber** grommet to create the sealing between the basket, the cover and the wires going in the connection area; **2 HelaCon Lux** for the power connection; **1 Q30R Cable Tie** to secure the wire connection.



APPLICATIONS

SpotClip-Box has been specially designed for passive houses applications. Suitable for both insulation in reel and blown-in. Suitable for both paneling and plasterboard. SpotClip is suitable for lighting **spot diameter up to 73mm** and **with a maximum height of 130mm**. Bulb range is limited to LED and fluo-compact.

PROPERTIES

Material	Polyamide 6.6 Heat stabilized (PA66HS)
Glow wire test	960 °C
Colour	Black (BK)
RoHS	Yes
Flammability	UL94-V2





TECHNICAL DATASHEET

Compatibility bulb/insulation	Rolled insulation	Loose / blow-in insulation
Halogen	✗	✗
LED	✓	✓
Fluorescent	✓	✓




Please check the local installation regulations supplied with the downlight and ensure that you conform to the following standards:



EN 60598-1
EN 60598-2-2

DIMENSIONS

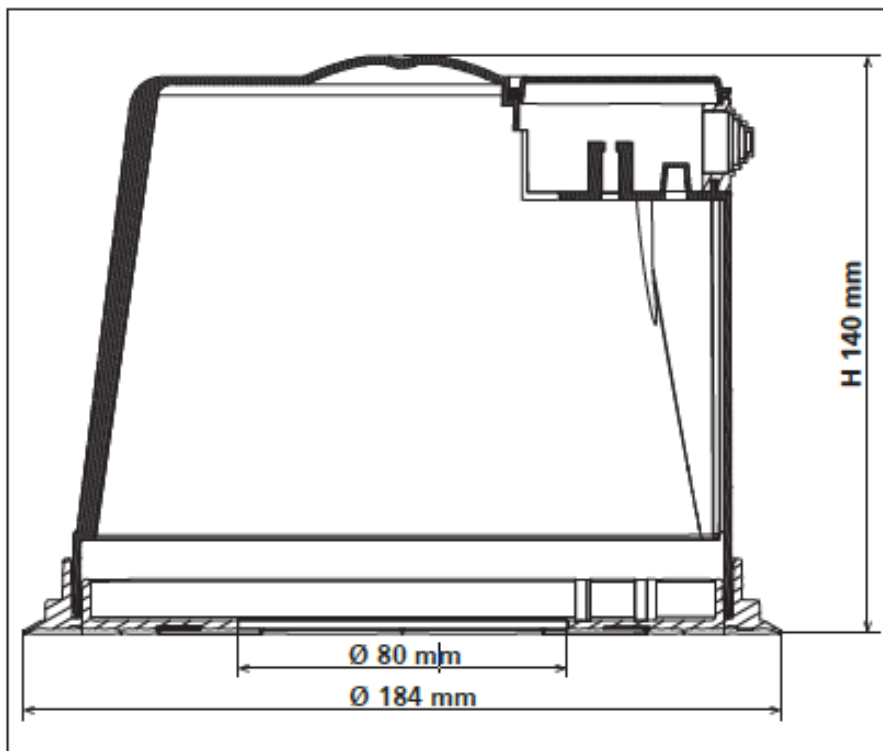

Article-No.	Type	Ø	H	Hole Ø	Pack Cont.		Drawing
					Box	Carton	
148-00123	SpotClip-Box	184	140	75 mm	1 part.	12 boxes.	