



ENGLISH


Datasheet

New 5.0mm Plug Straight 15A 7 way

RS Stock 874-4792



Dimensions: (mm)

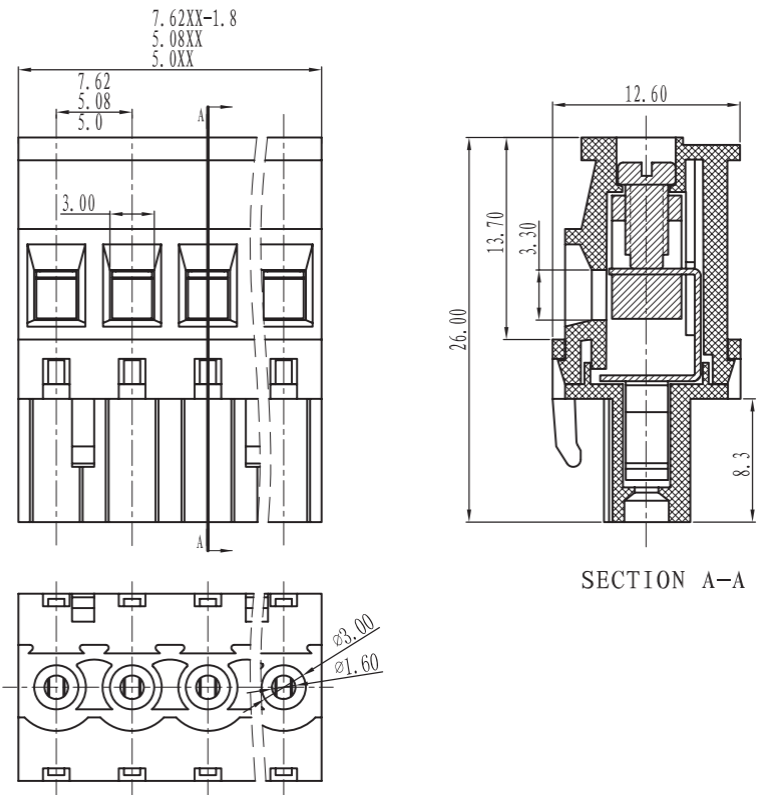



ENGLISH

Specifications

Electrical

Standard: UL IEC
Rated voltage: 300V 320V
Rated current: 15A 20A
Contact resistance: $20m\Omega$
Wire range: 28-14AWG $2.5mm^2$
Withstanding voltage: AC2000V/1Min
Insulation resistance: $500M\Omega$ /DC500V

Mechanical

Temp.Range: $-40^{\circ}C \sim +105^{\circ}C$
Torque: $0.5Nm$ ($4.51lb\cdot in$)
Strip length: 7-8mm

Dimensions

Pitch: 5.0mm, 5.08mm, 7.62mm
Poles: 02P-24P

Material

Housing: PA66, UL94V-0
Screws: M3, steel Zinc plated
Clamp: Brass, Ni plated
wire guard: Phosphor bronze, Ni plated