



Self-aligning ball bearings, cylindrical and tapered bore

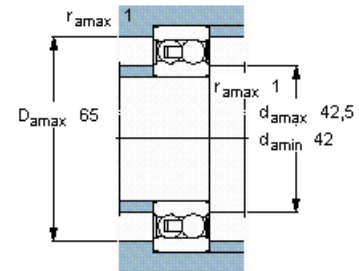

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
35	72	23	19	6	0,31	-	6300	0,41	2207 E-2RS1TN9

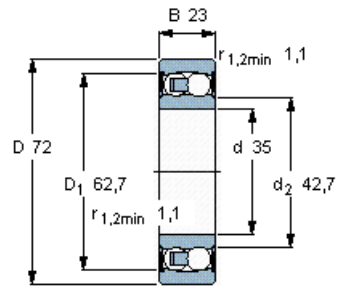

Calculation factors

- e 0,23
- Y₁ 2,7
- Y₂ 4,2
- Y₀ 2,8