

## Panel mounting frames - VS-PPC-F1-SCRJ-POBK-1RF - 1608210


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



SCRJ panel mounting frame, IP67, for push/pull interlocking, plastic, with the Freenet system, for square mounting cutout, with seal and SCRJ coupling, without mounting screws



### Key commercial data

Packing unit	1 pc
GTIN	 4 046356 159890
Weight per Piece (excluding packing)	17.4 g
Custom tariff number	85366990
Country of origin	Germany

### Technical data

#### Mechanical characteristics

Insertion/withdrawal cycles	≥ 500
Color	black

#### Ambient conditions

Ambient temperature (operation)	-20 °C ... 70 °C
Degree of protection	IP65/67

#### Material data

Inflammability class according to UL 94	V0
Housing material	PA-GF
Sealing material	NBR
Seal material	NBR

#### Electrical characteristics

Pollution degree	2
------------------	---

# Panel mounting frames - VS-PPC-F1-SCRJ-POBK-1RF - 1608210

## Classifications

eCl@ss

eCl@ss 4.0	24190219
eCl@ss 4.1	24190219
eCl@ss 5.0	27141137
eCl@ss 5.1	27141137
eCl@ss 6.0	27141137
eCl@ss 7.0	27141137
eCl@ss 8.0	27141137

## ETIM


ETIM 3.0	EC001121
ETIM 4.0	EC001121
ETIM 5.0	EC002310

## UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501


## Drawings

Dimensioned drawing

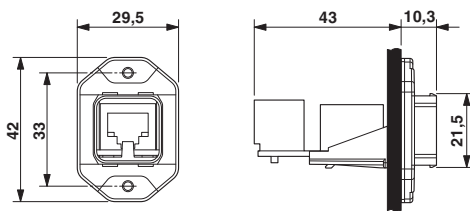

Push-Pull SCRJ panel mounting frame

Dimensioned drawing

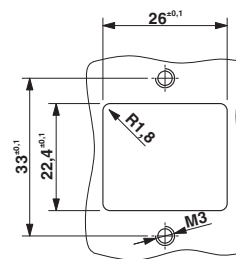

Panel cutout